

Hi-Spot 50

ES50 HM UK 240V 50W 50° GU10

0021312



Range features



PRODUCT OVERVIEW

Ordering number	0021312
Light colour	827 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	3000
Lamp finish	Aluminium
Lamp shape	Reflector
Dimmable	Yes
Cap/Base	GU10
Type	PAR16 (GU10)
EAN code	5410288213125
CRI (Ra)	100
Beam angle(°)	50
Colour temperature (K)	2700
Useful luminous flux (Rated) (lm)	300
Watt (Nominal) (W)	50
Voltage (V)	240

Hi-Spot 50

ES50 HM UK 240V 50W 50° GU10

0021312

DATA TABLE

General data

Technology	Halogen
Ordering number	0021312
Energy class	D
Energy saving lamp	No
Average life (Rated) (h)	3000
Average life (Nominal) (h)	3000
Lamp shape	Reflector
Lamp finish	Aluminium
Dimmable	Yes
Cap/Base	GU10
Type	PAR16 (GU10)
EAN code	5410288213125
Product name	ES50 HM UK 240V 50W 50° GU10
Lamp mercury content (mg)	0
Starting time (max) (s)	0
Warm-up time to 60% of full light (max) (s)	Instant Full Light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-3
IEC Reference 3	IEC 60630
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 12000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	100

Optical data

Light colour	827 Homelight
CRI (Ra)	100
Beam angle (Rated) (°)	50
Suitable for accent lighting	Yes
Beam angle(°)	50
Colour temperature (K)	2700
Useful luminous flux (Rated) (lm)	300
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	300
Peak intensity (cd)	500

Hi-Spot 50

ES50 HM UK 240V 50W 50° GU10

0021312

Electrical data

kWh per 1000 hours burning time	50
Watt (Rated) (W)	50
Watt (Nominal) (W)	50
Voltage (V)	240
Lamp power factor	1

Physical data


Weight (kg)	0.05
Lamp Length (mm) - C/L	55
Max. Lamp Diameter (mm) - D	50
Lamp dimension equal to filament lamp equivalent	Yes
Designed for optimum use in non standard conditions	No
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	6.20 x 4.80 x 4.80
Outer package dimensions (L x W x H) (cm)	50.00 x 27.00 x 14.00

Hi-Spot 50

ES50 HM UK 240V 50W 50° GU10

0021312

TECHNICAL DRAWINGS

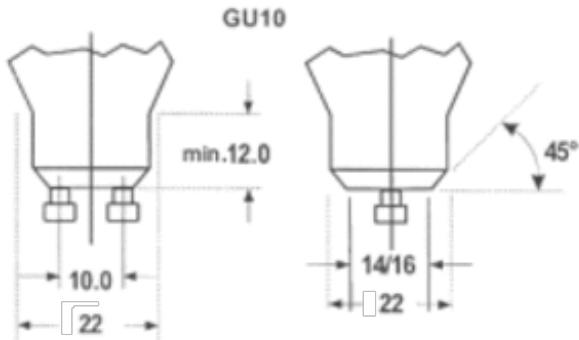

ENERGY LABEL

