


# LONG LIFE CUTTING MODERN AUTOMOTIVE STEEL

## EXPERT Vehicle Rescue Blades

### EXPERT

- ① Exceptional durability is built in with Bosch Carbide Technology
- ② First tooth designed to allow plunge cut
- ③ Tapered tip reaches deeper into tight spaces
- ④ Thick gauge blade offers extra robustness and stability

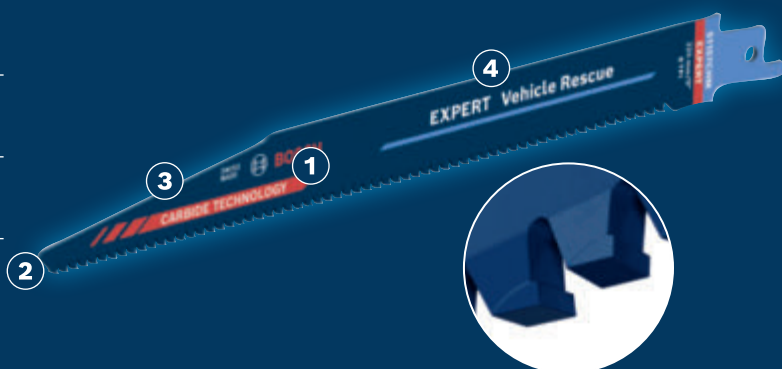

\* vs. Bosch S1122BF

 


# BOSCH

## EXPERT VEHICLE RESCUE S1157CHM BLADE



- Ideal for rescue cuts into a vehicle at a road accident site. Designed for specific cuts common in modern rescue techniques; for example cutting a car's B column and window; or creating a 'third door'
- Best for firefighters and rescue workers: long lasting and reliable
- Lasts up to 50x longer than Bosch S1122BF blade in tough materials
- Fits all S-shank reciprocating saws



| PRODUCT PROPERTIES |                   |                       |                             |                                          |                                          |                        | ORDERING INFORMATION |               |                        |                      |               |
|--------------------|-------------------|-----------------------|-----------------------------|------------------------------------------|------------------------------------------|------------------------|----------------------|---------------|------------------------|----------------------|---------------|
| Tooth spacing [mm] | Tooth pitch [TPI] | Dimensions LxWxT [mm] | Blade material abbreviation | Recommended min. material thickness [mm] | Recommended max. material thickness [mm] | Max. cut capacity [mm] | Packaging type       | Pack quantity | Minimum order quantity | Barcode 4 059 952... | Part number   |
| 3                  | 8                 | 225 x 20 x 1.35       | CT                          | 4                                        | 12                                       | 175                    | C1c                  | 1             | 1                      | 534 701              | 2 608 900 380 |
| 3                  | 8                 | 225 x 20 x 1.35       | CT                          | 4                                        | 12                                       | 175                    | C1c                  | 3             | 1                      | 534 718              | 2 608 900 381 |
| 3                  | 8                 | 225 x 20 x 1.35       | CT                          | 4                                        | 12                                       | 175                    | P1h                  | 10            | 1                      | 534 725              | 2 608 900 382 |



# BOSCH