

Han 48HPR mounting cover-PVD 1to2-3xM32

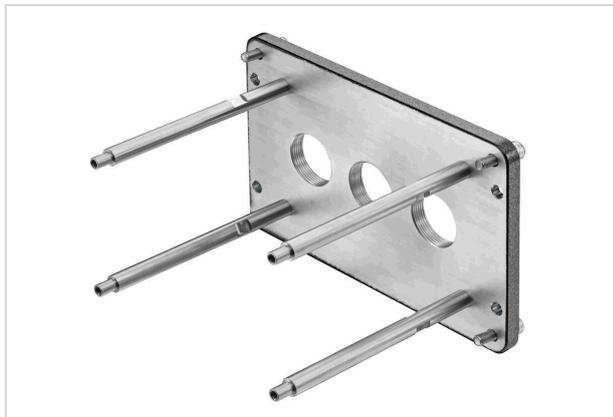


Image is for illustration purposes only. Please refer to product description.

Part number	19 40 148 9828
Specification	Han 48HPR mounting cover-PVD 1to2-3xM32
HARTING eCatalogue	https://harting.com/19401489828

Identification

Category	Hoods / Housings
Series of hoods/housings	Han [®] HPR PYD
Type of hood/housing	Mounting cover
Description of hood/housing	Distance bolt M6

Version

Size	48 B
Number of cable entries	3
Cable entry	3x M32
Locking type	Screw locking
Field of application	Hoods/housings for harsh outdoor environments

Technical characteristics

Tightening torque	4 Nm Distance bolt
Tightening torque (screw locking)	4 Nm
Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65 IP68 IP69 / IPX9K acc. to ISO 20653

Material properties

Material (hood/housing)	Aluminium Corrosion resistant
-------------------------	----------------------------------



Pushing Performance
Since 1945

Material properties

Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 9005 (jet black)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08) + A1 (2023-10)
Requirement set with Hazard Levels	R1 (HL 1-3) R7 (HL 1-3)

Specifications and approvals

Approvals	CE
-----------	----

Commercial data

Packaging size	1
Net weight	946.5 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140173606
eCl@ss	27440202 Shell for industrial connectors
ETIM	EC000437
UNSPSC 24.0	39121466