

FEATURES

- Operating temperature range is from - 60 °C to +300°C
- RoHS and REACH compliant
- Silicon free

RS PRO PLUG FOR UNIVERSAL FITTINGS

RS Stock No.: 2312646



RS PROfessionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO plug for universal fittings is made up of brass.

General Specifications

Product Type	Plug Fitting
Accessory Type	Plug Assembly
Material	Brass
Applications	Compressed Air, Pneumatic Automation, Industrial water circuits, Inert Gases, Fluids, Steam, Vacuum

Mechanical Specifications

Overall Length	11.5mm
Tube Size	10mm

Operation Environment Specifications


Maximum Temperature	+300°C
Minimum Temperature	-60°C

Approvals

Standards Met	RoHS and REACH Compliant
---------------	--------------------------

Similar Products

Parameters	2312535	2312536
Brand	RS PRO	RS PRO
Product Type	Adapter	Adapter
Accessory Type	Plug Connector	Plug Connector
Material	Nickel Plated Brass	Nickel Plated Brass
Maximum Pressure	75bar	50bar
Overall Length	13.5mm	14.5mm
Tube Size	9.5mm	10mm
Threaded Connection	3/8in Male	1/2 in Male
Threaded Connection - Thread Size	3/8in	1/2in
Wrench Size	19mm	24mm
Maximum Temperature	+300°C	+300°C
Applications	Compressed Air, Pneumatic Automation, Industrial water circuits, Inert Gases, Fluids, Steam, Vacuum	Compressed Air, Pneumatic Automation, Industrial water circuits, Inert Gases, Fluids, Steam, Vacuum

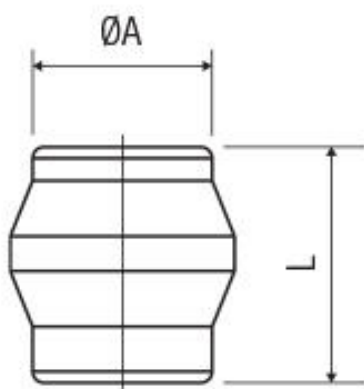

Tube	L	Pack.
10	11.5	50

