
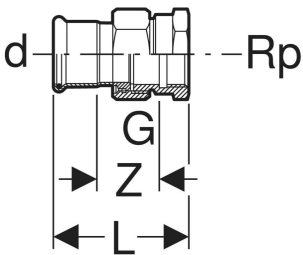


Geberit Mapress Carbon Steel adaptor union with female thread

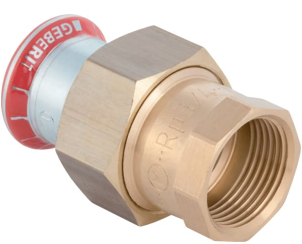

Example image

APPLICATION PURPOSES

- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For extinguishing water (wet)
- For sprinklers (wet)
- For compressed air (oil purity class 3)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Outside zinc-plated
- Union nut made of brass
- Adaptor made of gunmetal
- Seal ring made of CIIR, black
- Flat gasket made of EPDM

- Pressing socket with transparent protection plug

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Non-alloy steel 1.0034 E195 (EN 10305)

Art. no.	DN	d, ø mm	Rp "	G "	L cm	Z cm
25300	12 / 15	15	1/2	3/4	5.8	2.3
25302	15	18	1/2	3/4	5.8	2.3
25304	20	22	3/4	1	6.3	2.3
25305	20 / 25	22	1	1	6.6	3

Art. no.	DN	d _ø mm	R _p "	G "	L cm	Z cm
25306	25	28	1	1 1/4	7.1	3.3
25307	32	35	1 1/4	1 1/2	7.7	3.5
25308	40	42	1 1/2	1 3/4	8.2	3.1
25309	50	54	2	2 3/8	9.5	3.4