



Connectors > Connector Accessories > Connector Strain Relief



Strain Relief Accessory Type: **Cable Clamp**

Primary Product Material: **Carbon Steel**

Number of Positions: **26**

Thread Size: **4-40**

Packaging Method: **Bag**

Features

Product Type Features

Strain Relief Accessory Type	Cable Clamp
------------------------------	-------------

Configuration Features

Number of Positions	26
---------------------	----

Body Features

Cable Exit Angle	180°, 90°
Primary Product Plating Material	Nickel
Primary Product Material	Carbon Steel

Mechanical Attachment

Thread Size	4-40
-------------	------

Dimensions

Product Width	19.05 mm[.75 in]
Product Length	69.44 mm[2.734 in]
Product Height	41.28 mm[1.625 in]

Usage Conditions

--	--



Operating Temperature Range	-55 – 150 °C[-67 – 302 °F]
-----------------------------	----------------------------

Packaging Features

Packaging Method	Bag
Packaging Quantity	1

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




Also in the Series | AMP M Series

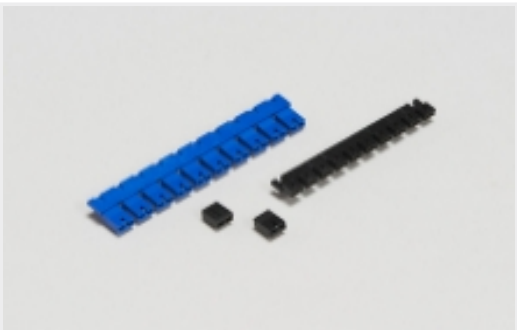

Board-to-Board Jumpers & Shunts(5)



Connector Contacts(51)

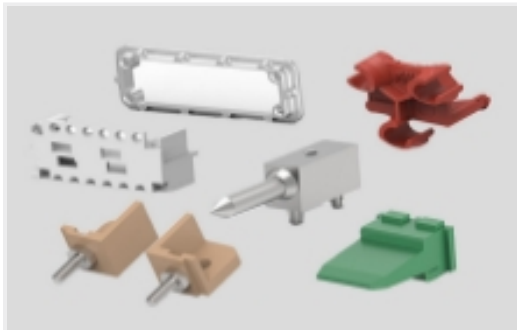

Connector Hardware(46)



Power Contacts(51)



Rectangular Connector Housings(77)




Rectangular Power Connectors(82)



Standard Rectangular Connectors(81)

Customers Also Bought

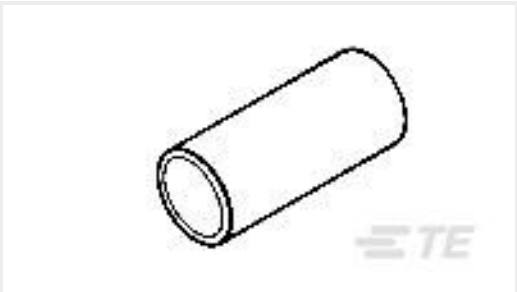


TE Part #1-332056-0
FERRULE, SUB MIN



TE Part #1-1625892-0
3W SM M/OX 5% 10K



TE Part #770069-1
02P .093 COMM P&S PLUG .248CL

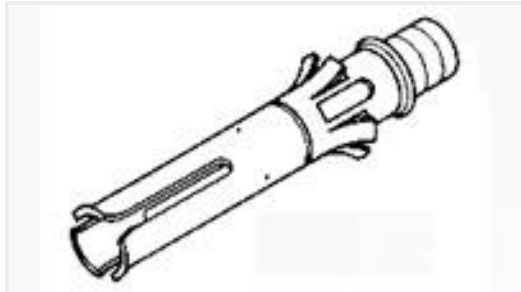

TE Part #51565-1
SUB MIN SOCKET




TE Part #60620-1
CMNL PIN 20-14 TPBR L/P



TE Part #1318111-1
DYNAMIC D-2 TAB CONT M L/P




TE Part #696050-1
PG 8 R 10

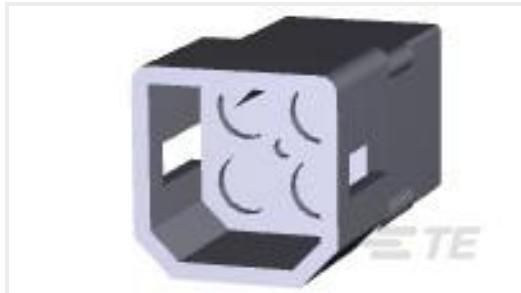

TE Part #770842-1
04P .093 COMM P&S PLUG



TE Part #60619-1
CMNL SOK PTPBR L/P

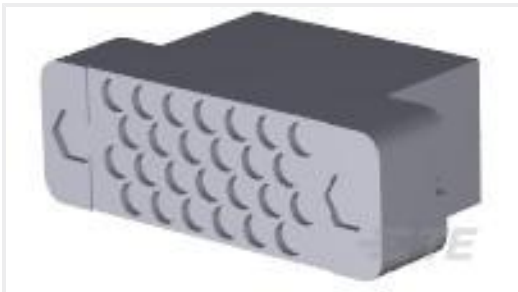

TE Part #200512-2
FEMALE BLOCK 26 PL

Documents



Product Drawings

26 PL. STRAIN REL. CLAMP

English

CAD Files

Customer View Model

ENG_CVM_201845-2_E.3d_igs.zip

English

Customer View Model

ENG_CVM_201845-2_E.3d_stp.zip

English

Customer View Model

ENG_CVM_201845-2_E.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_201845-2_J.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_201845-2_J.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_201845-2_J.2d_dxf.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Instruction Sheets

Instruction Sheet (U.S.)

English

STRAIN RELIEF CLAMP CATALOG NO. 201845 FOR 26 POSIITON SERIES "M"

English