


Data sheet

Commercial Art.No.: 56.106.0055.0

Measuring-disconnecting terminal WKN 6 TK

Measuring-disconnecting terminal with Screw connection for mounting on TS 35, nominal cross section: 6 mm², Width: 8 mm, Color: grey

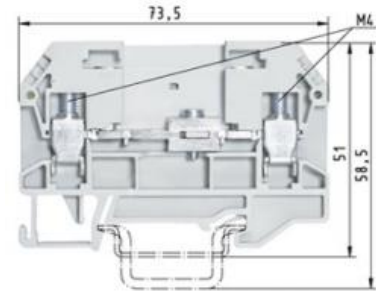

Commercial Art.No.	56.106.0055.0
EAN	4049088003141
Order Unit	50

Certificates / Approvals

Technical data

General

Nominal cross section	6 mm ²
Colour	Grey
Number of levels	1
Number of clamp positions per level	2
Width/grid dimension	8 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	No

Technical data

Rated current	41 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Closing plate required	Yes
Type of insulation material	Thermoplastic
Length	73.5 mm

Connection Data

Connection type 1	Screw connection
Connection type 2	Screw connection
Minimum cross section solid	0.5 mm ²
Maximum cross section solid	10 mm ²
Minimum cross section fine stranded	0.5 mm ²
Maximum cross section fine stranded	10 mm ²
Wire strip length	12 mm
Torque conductor mounting	1.2 Nm

Note

Integrated test socket	No
------------------------	----

Classification

ECLASS 8.1	27141126
ETIM 7.0	EC000902
ETIM 6.0	EC000902
ETIM 5.0	EC000902
ETIM 4.0	EC000902
ETIM 3.0	EC000902

Accessories

Commercial Art.No.:	Article-type description:	Description:
----------------------------	----------------------------------	---------------------

Fits with

Commercial Art.No.:	Article-type description:	Description:
----------------------------	----------------------------------	---------------------