


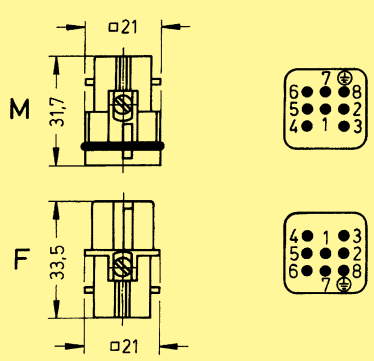

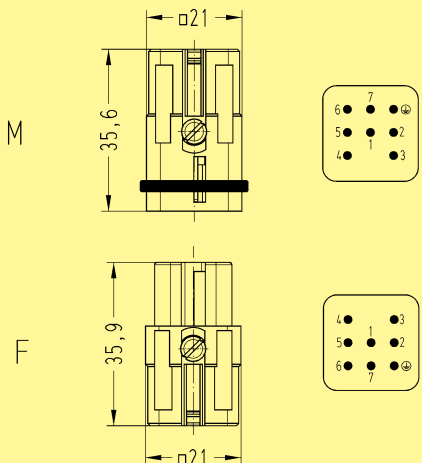

 
Number of contacts

7 +



Inserts

Han
D/DD

| Identification | Series | Part number | | Drawing | Dimensions in mm |
|--|--------|-----------------------|-----------------------|---|------------------|
| | | Male insert (M) | Female insert (F) | | |
| <p>Crimp terminal</p> <p>Order crimp contacts separately (see Technical characteristics on page 02.04)</p>  <p>Attention Only for thermoplastic hoods/housings</p> | Han D® | 09 21 007 3031 | 09 21 007 3131 | <p>Contact arrangement view from termination side</p>  | |
| <p>Han® 7 D Quick Lock</p>  <p>Attention Only for thermoplastic hoods/housings</p> | Han D® | 09 21 007 2632 | 09 21 007 2732 | <p>Contact arrangement view from termination side</p>  | |
| <p>Coding pin</p>  | | | 09 33 000 9915 | <p>Coding pin</p>  <p>Use of the coding pin prevents incorrect mating to other connectors of the same type. The male pin should be omitted from the opposing cavity in the male insert.</p> | |

Stock items in bold type