



Brand of NTN corporation

Technical data

USPE206

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US.206.G2, PE206

VISUAL (S)

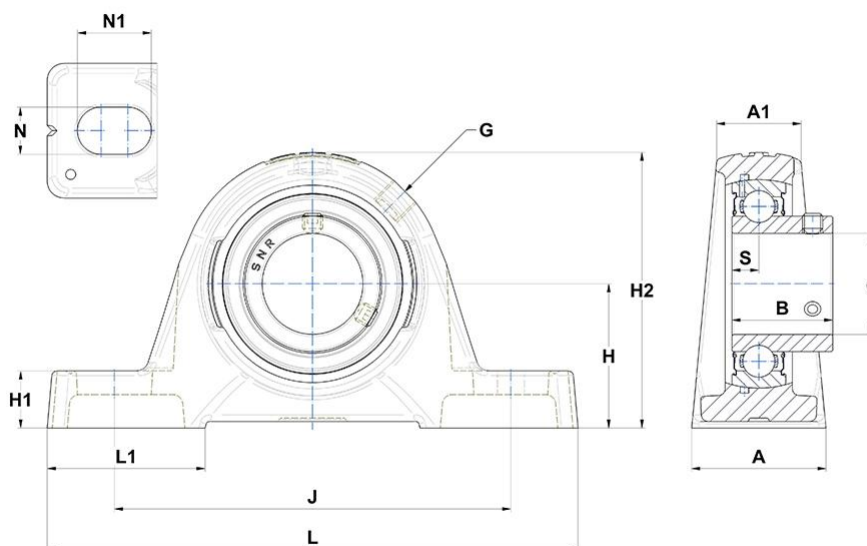

PRODUCT DEFINITION

Brand	SNR
A - Housing width	40 mm
A1 - Housing top width	25 mm
B - Width of Inner Ring	30 mm
d - Shaft diameter	30 mm
G - Grease fitting	R1/8"



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H - Distance mounting base to centerline spheric. seating diam.	42,9 mm
H1 - Housing foot height	17 mm
H2 - Housing height	82 mm
J - Mounting holes distance	118 mm
L - Housing length	158 mm
L1 - Housing foot length	47 mm
N - Mounting hole dimension	14 mm
N1 - Mounting hole length	22 mm
S - Distance front side/bearing centre	8 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	19500000 mN
C0 - Static load rating	11200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,07 kg
Recommended tightening torque for set screw	5.5 N-m

