


Features

- NiCr-Ni "K" Type Thermocouples
- Max. operating temperature 400°C
- Protection tube AISI304(DIN1.4301) Stainless Steel
- Sensor type DIN/IEC-584 "K" Type
- Cable type Fiber glass+Fiber glass+Braided
- Tube Diameter 6mm
- Immersion Length 50mm
- Cable Length 2meter

RS PRO Bayonet Bore "K" Type Thermocouples

RS Stock No: 0350388

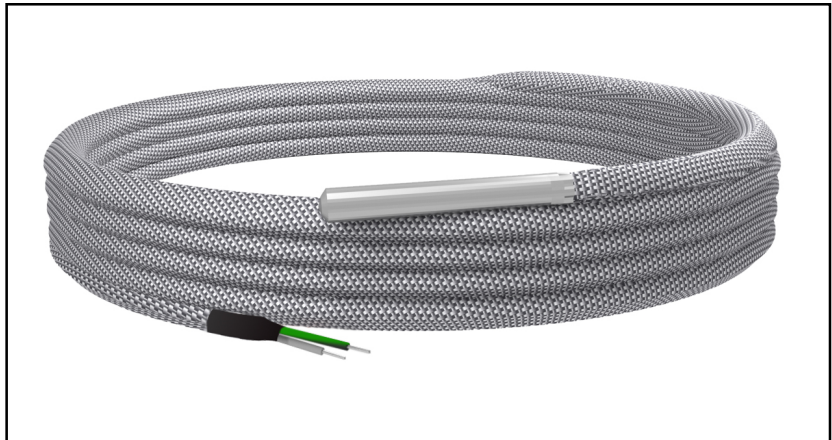

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Standard Bayonet "K" Type Thermocouples Temperature Sensor

Diameter(M): 6mm

Immersion Length(L): 50mm

Cable Length(K): 2m

Applications Fields

- Machinery Manufacturing
- Panel Manufacturing
- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications


General Specifications

| | |
|----------------------------|--|
| Max. Operating Temperature | 0 °C / +400 °C |
| Standard cable types | Fiber glass + fiber glass + braided wire |
| Sensor type | "K" Type Thermocouples (DIN/IEC-584) |
| Protection tube material | AISI304 (DIN1.4301) Stainless Steel |

Mechanical Specifications

| | |
|----------------------|------|
| Diameter (M) | 6mm |
| Immersion Length (L) | 50mm |
| Cable Length (K) | 2m |

Electrical Connection

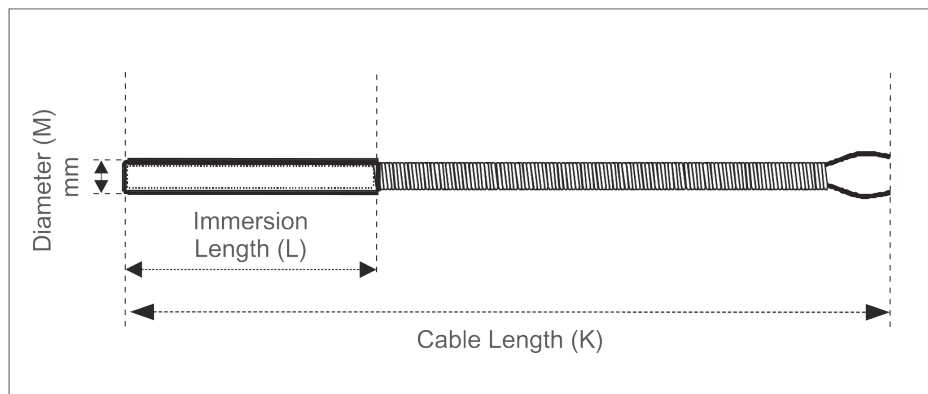

Thermoelement Connections

