


# Product data sheet

Specifications

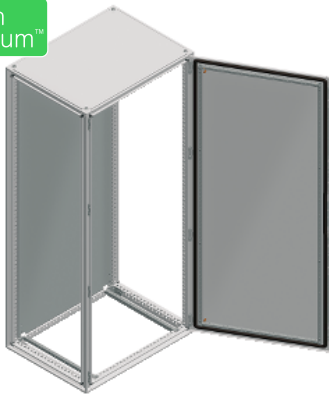

## Spacial SF enclosure without mounting plate - assembled - 2200x800x800 mm

NSYSF22880

### Main

Range	Spacial
Extended range	Spacial SF
Application	Multi-purpose
Product or component type	Suitable enclosure
Enclosure nominal height	2200 mm
Enclosure nominal width	800 mm
Enclosure nominal depth	800 mm
Enclosure mounting	Floor-standing
Device composition	2 sliding rails 4 mounting plate bracket 1 structure 1 door 1 locking system with handle: door 1 rear panel 1 roof

### Complementary

Structure type	Formed from a single section Perforated structure with a pitch of 25 mm Panels and doors built into the structure Vertical uprights joined with top and bottom frames
Door type	Plain front
Number of doors	Front: 1 door(s)
Door opening side	Reversible (120 °)
Lock type	4 points lock, handle with 5 mm double bar insert front door
Mounting plate description	Without mounting plate
Type of gland plate	Without gland plate
Accessibility for operation	Sides of enclosure Front Rear
Removable parts	Door by screws hinge Rear panel by screws Roof by screws Mounting plate bracket by screws Sliding rail by screws
Material	Frame: galvanised steel Uprights: galvanised steel Door: sheet steel Panels: sheet steel Hinge: zamak

Handle: polyamide 6 with 30 % fibre glass

<b>Surface finish</b>	Epoxy-polyester powder
<b>Colour</b>	Enclosure: grey (RAL 7035) Handle: black (RAL 9005)
<b>Net weight</b>	121.900 kg

## Environment

<b>Standards</b>	IEC 62208
<b>NEMA degree of protection</b>	NEMA 3R/12
<b>IP degree of protection</b>	IP55 conforming to IEC 60529
<b>IK degree of protection</b>	IK10 conforming to IEC 62262

## Packing Units

<b>Unit Type of Package 1</b>	PCE
<b>Number of Units in Package 1</b>	1
<b>Package 1 Weight</b>	121.9 kg
<b>Package 1 Height</b>	233 cm
<b>Package 1 width</b>	84.5 cm
<b>Package 1 Length</b>	89 cm

## Offer Sustainability

<b>Sustainable offer status</b>	Green Premium product
<b>REACH Regulation</b>	<a href="#">REACH Declaration</a>
<b>REACH free of SVHC</b>	Yes
<b>EU RoHS Directive</b>	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
<b>Mercury free</b>	Yes
<b>RoHS exemption information</b>	<a href="#">Yes</a>
<b>China RoHS Regulation</b>	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information
<b>Environmental Disclosure</b>	<a href="#">Product Environmental Profile</a>

## Contractual warranty

<b>Warranty</b>	18 months
-----------------	-----------