

LED, base BA15d, green, 230 V AC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS		
product designation	LED		
General technical data			
type of voltage of the operating voltage	AC		
operating voltage			
• 1 at AC at 50 Hz rated value			
• 1 at AC at 60 Hz rated value	230 V		
relative positive tolerance of the operating voltage	10 %		
relative negative tolerance of the operating voltage	-15 %		
reference code according to EN 61346-2	P		
Lamp			
type of light source	LED		
light intensity	1.26 cd		
socket design	BA 15d		
Enclosure			
height	45 mm		
width	20 mm		
outer diameter of the signal column element	70 mm		
color	green		
Ambient conditions			
ambient temperature during operation	-20 ... +60 °C		
Approvals Certificates			
General Product Approval		other	Environment




[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4458-6XC>
Cax online generator
<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4458-6XC>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8WD4458-6XC>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

-P

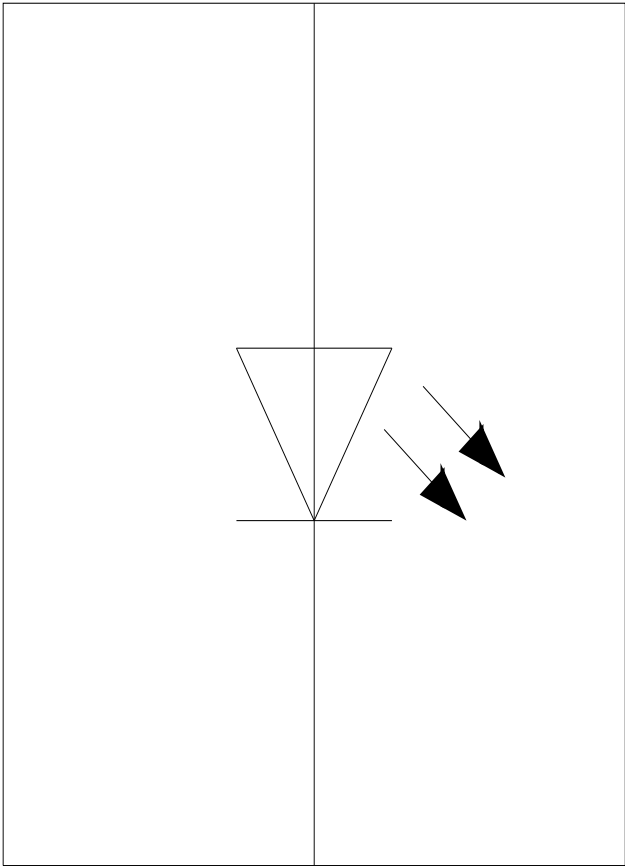

last modified:

4/1/2025 