


## Datasheet

# 1 x 58 W Hazardous Area Light Fitting, Anti-Corrosive, 2, Fluorescent, Temp T4, 240 V ac

RS Stock 539-6974



### Dimensions (mm):

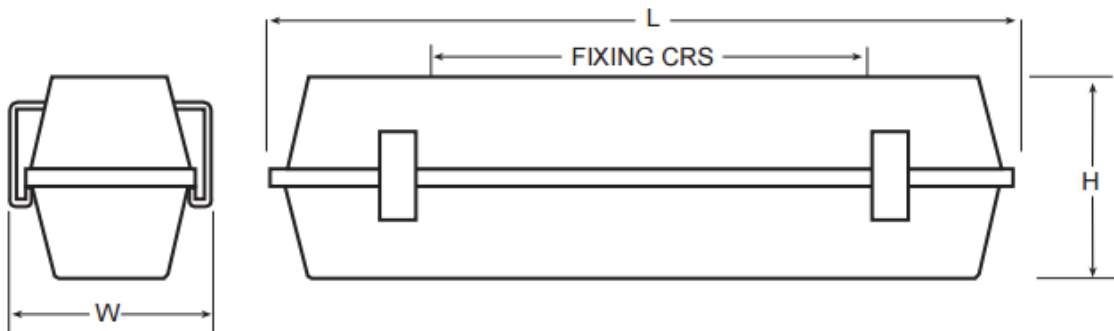

#### Features

- Innovative design for easy re-lamping.
- Robust lightweight, slimline and compact construction for T8 lamps.
- Full range standards and emergency luminaires.
- Suitable for Gas and Dust areas.
- Unrestricted breathing enclosure – i.e. no need for annual gasket inspection and pressure testing.
- High frequency ballast as standard, i.e. 220-250v 50/60Hz.
- Tough GRP bodies, robust polycarbonate diffuser with easy access for tube replacement via stainless steel diffuser clip mechanism.
- Push fit gear tray for simple & quick installation.
- Drill through rear bolt fixing or optional stainless steel snap action fixing which provides variable centres.
- 2 x M20 cable entries (1 plugged) as standard with 3 wire & earth terminals for 2.5mm.