




8155-1/2
ERGO™ 1/2" Reversible Ratchets
with 60 Teeth and 6° Action Angle



PRODUCT DETAILS

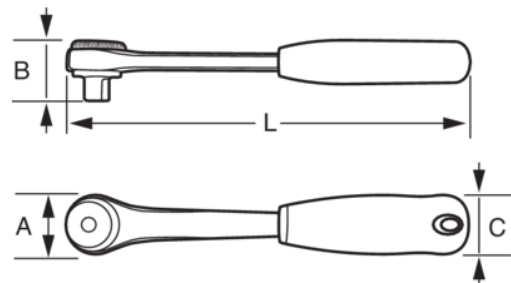


 

- 60 teeth/6° action angle
- Quick-release function
- A ring switch provides an easy one-handed change of the working direction
- A quick drive disc gives fast nut rotation
- Comfortable non-slip bi-material handle with hanging hole for easy storage
- Made from high-performance alloy steel, precision forged and heat treated to provide optimum durability
- Highly polished finish
- Spare parts available
- SB: Retail packed on an anti-theft plastic card
- Standards: ISO 3315/1174-2, DIN 3122/3120
- Developed according to the Bahco scientific ERGO™ process
- Comfortable two-component handle giving an excellent grip
- Maximum comfort with minimum effort thanks to ergonomic design
- Quick-release function for easy and safe operation
- The socket that is safely attached during work is quickly released at the press of a button
- 60 teeth / 6° action angle for outstanding strength and accessibility



Follow the Fish!



PRODUCT ATTRIBUTES

Product				A	B	C		
8155-1/2	1/2 in	6 °	60	43,4 mm	39 mm	30 mm	262 mm	575 g
SB8155-1/2	1/2 in	6 °	60	43,4 mm	39 mm	30 mm	262 mm	575 g

Follow the Fish!

