
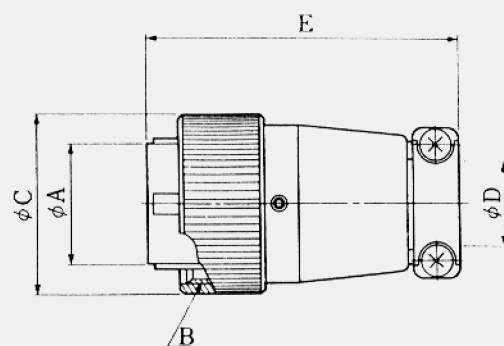


JR21PK-16S

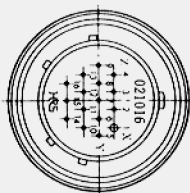

Unit: mm

HRS No.	Part No.	No. of Pin	φA	B	φC	φD	E	JIS No.
114-0501-7	JR13PK-3P	3	12.7	M18 x 1	21.8	8.5	45.5	CNR01SPM013003
114-0502-0	JR13PK-5P	5	12.7	M18 x 1	21.8	8.5	45.5	CNR01SPM013005
114-0503-2	JR16PK-7P	7	16.3	M22 x 1	25.8	11.8	49.5	CNR01SPM016007
114-0504-5	JR16PK-10P	10	16.3	M22 x 1	25.8	11.5	49.5	CNR01SPM016010
114-0505-8	JR21PK-10P	10	20.5	M26 x 1	29.8	15	53.5	CNR01SPM021010
114-0506-0	JR21PK-16P	16	20.5	M26 x 1	29.8	15	53.5	CNR01SPM021016
114-0507-3	JR25PK-16P	16	24.7	M30 x 1	33.8	18	56.5	CNR01SPM025016
114-0508-6	JR25PK-24F	24	24.7	M30 x 1	33.8	18	56.5	CNR01SPM025024
114-0552-8	JR25PK-4P	4	24.7	M30 x 1	33.8	18	56.5	—
114-0554-3	JR25PK-5P	5	24.7	M30 x 1	33.8	18	56.5	—
114-0556-9	JR32PK-8P	8	24.7	M30 x 1	33.8	18	56.5	—

HRS No.	Part No.	No. of Pin	φA	B	φC	φD	E	JIS No.
114-0509-9	JR13PK-3S	3	12.7	M18 x 1	21.8	8.5	45.5	CNR01SPF013003
114-0510-8	JR13PK-5S	5	12.7	M18 x 1	21.8	8.5	45.5	CNR01SPF013005
114-0511-0	JR16PK-7S	7	16.3	M22 x 1	25.8	11.5	49.5	CNR01SPF016007
114-0512-3	JR16PK-10S	10	16.3	M22 x 1	25.8	11.5	49.5	CNR01SPF016010
114-0513-6	JR21PK-10S	10	20.5	M26 x 1	29.8	15	53.5	CNR01SPF021010
114-0514-9	JR21PK-16S	16	20.5	M26 x 1	29.8	15	53.5	CNR01SPF021016
114-0515-1	JR25PK-16S	16	24.7	M30 x 1	33.8	18	56.5	CNR01SPF025016
114-0516-4	JR25PK-24S	24	24.7	M30 x 1	33.8	18	56.5	CNR01SPF025024
114-0553-0	JR25PK-4S	4	24.7	M30 x 1	33.8	18	56.5	—
114-0555-6	JR25PK-5S	5	24.7	M30 x 1	33.8	18	56.5	—
114-0557-1	JR25PK-8S	8	24.7	M30 x 1	33.8	18	56.5	—