


## TECHNICAL DATA SHEET

### SECUMAX 363 NO. 363001

#### Safety technology

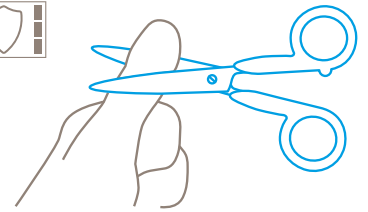

#### Safe special ground - maximum safety

The cutting edges are not angled, but straight ground. This means: No danger for your fingers. Therefore our safety scissors all carry the name SECUMAX = maximum safety.



#### SMALL SAFETY SCISSORS WITH FINGER-FRIENDLY SPECIAL GRINDING.

**Order No.** 363001.00

#### Precise to the millimeter. In many regards.

Our safety scissors for extra fine and targeted cuts. It is playfully easy to direct, using your thumb and forefinger only. And just like its big brothers, the lightweight cuts through cardboard, paper, film, fabrics, yarn and strapping band. Your fingers and hand are protected against injuries by the special way the scissors have been sharpened in addition to the rounded tips.

#### Sharp, but not dangerous!

Take a good look at the cuts. Noticed anything? None of them have been cut at an angle, as all of the cuts are at right-angles. Therefore you cannot cut yourself, only the large range of potential materials.

#### Non-rusting stainless steel

You will be able to use your scissors for a very long time as the metal parts are made from non-rusting stainless steel. The handles have been coated in a plastic reinforced with fibreglass. Another guarantee for a long service life.

#### Comfortable working

„The experts call them “eyes” and these are the small openings in which you insert your fingers to securely hold the scissors. The “soft-grip” on the insides also helps to ensure comfortable and non-slip working.“


#### Short cutting

In brief: this is true precision! This makes the SECUMAX 363 especially suitable for precise, sophisticated cutting. The scissors will not drift away from your line, even when you want to cut in the smallest corners.

#### Sturdy connection

A matter of course for quality scissors: Both of the cutting edges are held together by a real screw. This ensures stable cohesion and permanent high cutting power.

## USAGE

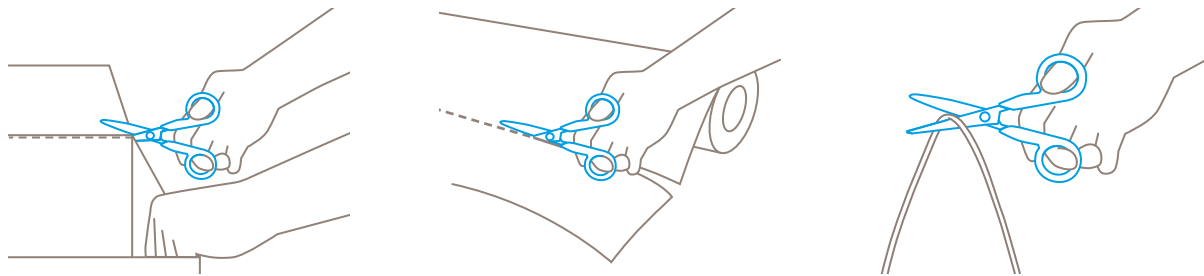

## PRODUCT FEATURES

### Technical features



Maximum safety



Very ergonomic



Cutting edge length  
(56 mm)



Soft-grip



For right and left hander



Precision cutting



stainless

### Main cutting materials



Cardboard: 1-ply



Plastic strapping band



Layers of foil or paper



Textile, material



Yarn, cord



Wrapping, stretch, and  
shrink foil

## SERVICES OFFERED



Training video



Technical data sheet



Consulting service

## PRODUCT AND PACKAGING DETAILS

|                        |                   |                            |                        |
|------------------------|-------------------|----------------------------|------------------------|
| Order No.              | NO. 363001.00     | Packaging unit             | 1 on self-service card |
| Knife size (L x W x H) | 134 x 8 x 65.5 mm | Size self-service card     | 90 x 185 mm            |
| Weight knife           | 39.5 g            | Weight self-service card   | 48.3 g                 |
| Basic material         | Stainless steel   | EAN Code self-service card | 4002632921315          |
|                        |                   | Quantity in outer pack     | 10 scissors            |
|                        |                   | Weight outer pack          | 511.7 g                |
|                        |                   | EAN Code outer pack        | 4002632972638          |
|                        |                   | Customs tariff number      | 82130000               |

## SAFETY INSTRUCTIONS

---

Please read these instructions and keep them safe so that you can use your new MARTOR scissors safely and in the best possible way.

**1. General application instructions:** Please always use the product carefully for manual cutting work only and not for any purposes other than those that are intended. Please take the correct handling and the proper use of the knives into account in this regard. As an additional safety measure, we recommend the wearing of safe gloves.

**2. Special application instructions to avoid the danger of injuries:** Always use the safety scissors with great caution even when the specially sharpened cutting edges seem to offer protection from cut and stab injuries. Please only use the scissors for the above-mentioned materials in an appropriate fashion and always carefully. With this in mind, respect the correct handling and usage of the safety scissors. Any other usage can lead to damaging the product or even other nearby items. Through inappropriate usage, e.g. knocks, bangs or falling from even a low height, the scissors can become damaged. In particular, the scissors must not be used in a way that can cause a crushing hazard to the hands or other limbs.

Always guide the safety scissors in a straight line away from you and keep them at a constant suitable angle.

**3. Storage/Nonuse of the scissors:** When you are not using the scissors, keep them in a safe place. If the scissors are visibly damaged, do not use them.

**4. Care advice:** Protect the scissors from moisture and heat and store in a dry place. From time to time, put a drop of oil in the screw slots so that the cutting action remains smooth.

**CAUTION:** No liability will be assumed for consequential losses. Subject to technical changes and errors! This scissor does not belong in the hands of children!

## ACCESSORIES

---

### BELT HOLSTER S WITH CLIP NO. 9920



What do you do with your cutting tools when you are not actually using them? The MARTOR BELT HOLSTER S is a robust holder that allows you to carry all compact MARTOR knives as well as our safety scissors at all times. In addition, the compartments are designed to allow you to load different tools: for example you can also carry a pen or a pack of blades. The MARTOR BELT HOLSTER is the ideal place to stow your tools safely when moving from A to B - and have them at hand, as soon as they are required.

## MANUFACTURER

---

MARTOR KG | Lindgesfeld 28 | 42653 Solingen | Germany  
T +49 212 73870-0 | [info@martor.de](mailto:info@martor.de) | [www.martor.com](http://www.martor.com)