

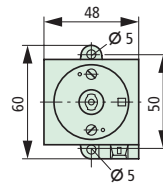


Service distribution board mounting

T0.../IVS


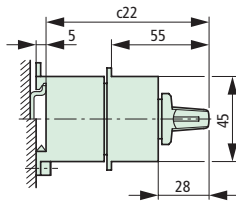


Drilling dimensions
Base



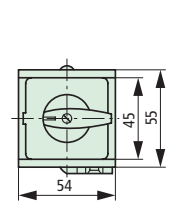


Rear mounting




T0.../Z
T3.../Z

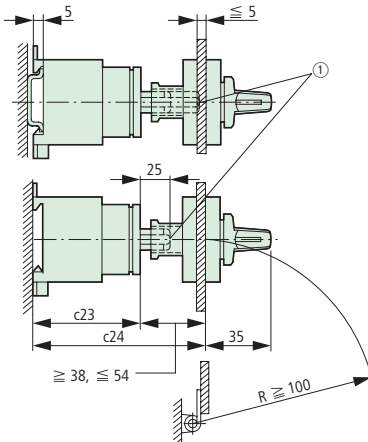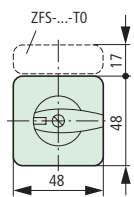

T0

 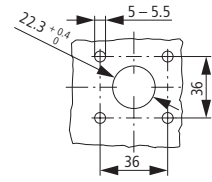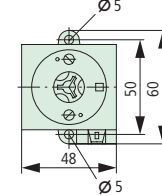

T3

 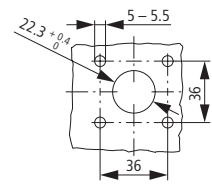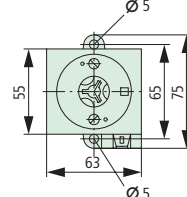

① Can be extended using ZAV-T0,
≧ 4 × 25 = 100 mm

Type	c20	c21	c22	c23	c24 ≧/≦	c24 with ≧ 4 ZAV	c25
T0-1...	41	61	77	48	86 - 102	202	72
T0-2...	50	70	87	57	96 - 112	212	72
T0-3...	60	80	96	67	105 - 121	221	91
T0-4...	69	89	106	76	115 - 131	231	91
T0-5...	79	99	115	86	124 - 140	240	-
T0-6...	88	108	125	95	134 - 150	250	-
T0-7...	98	118	134	105	143 - 159	259	-
T0-8...	107	127	144	114	153 - 169	269	-
T0-9...	117	137	154	124	162 - 178	278	-
T0-10...	126	146	163	133	172 - 188	288	-
T0-11...	136	156	173	143	181 - 197	297	-

Depth of one contact unit: 9.5 mm



Type	c20	c21	c22	c23	c24 ≧/≦	c24 with ≧ 4 ZAV	c25
T3-1...	44	64	80	51	86 - 105	205	79
T3-2...	56	76	92	63	101 - 115	216	79
T3-3...	67	87	103	74	112 - 128	228	101
T3-4...	79	99	115	86	124 - 139	239	101
T3-5...	90	110	126	97	135 - 151	251	-
T3-6...	102	122	138	109	147 - 162	262	-
T3-7...	113	133	149	120	158 - 174	274	-
T3-8...	125	145	161	132	170 - 185	285	-
T3-9...	136	156	172	143	181 - 196	296	-
T3-10...	148	168	184	155	193 - 208	308	-
T3-11...	159	179	195	166	204 - 219	319	-

Depth of one contact unit: 11.5 mm


Moeller HPL0211-2004/2005

Flush mounting main switches

T0.../EA/SVB
T3.../EA/SVB

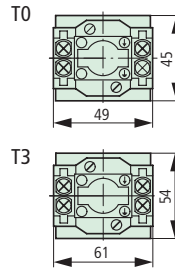
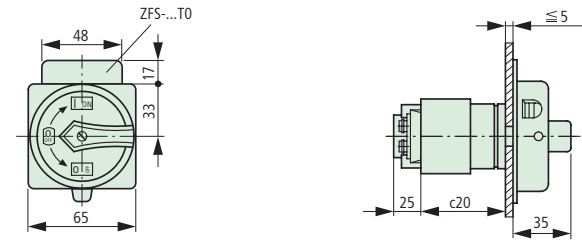


Drilling dimensions
Door

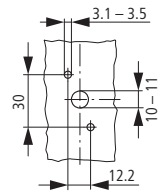


Rear mounting main switches


T0.../V/SVB
T3.../V/SVB

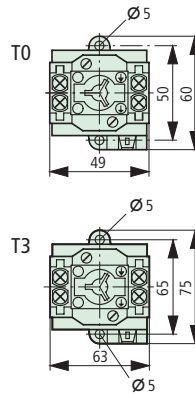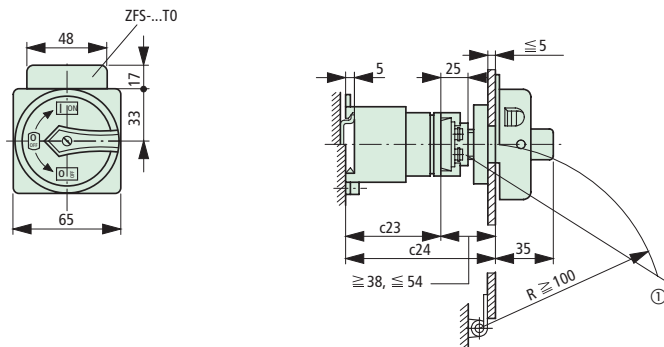

Drilling dimensions
Base

 

Drilling dimensions
Door

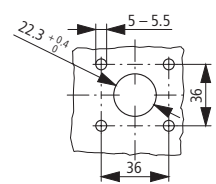


① Interlock can be extended using ZVV-T0 + ZAV-T0, ≅ 4 × 25 = 100 mm




Surface mounting


T0.../11

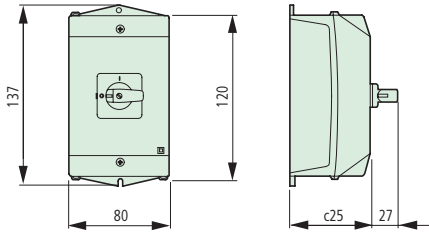


Drilling dimensions
Base

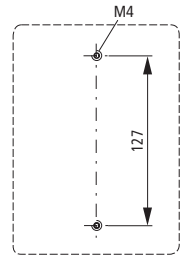

T3.../12

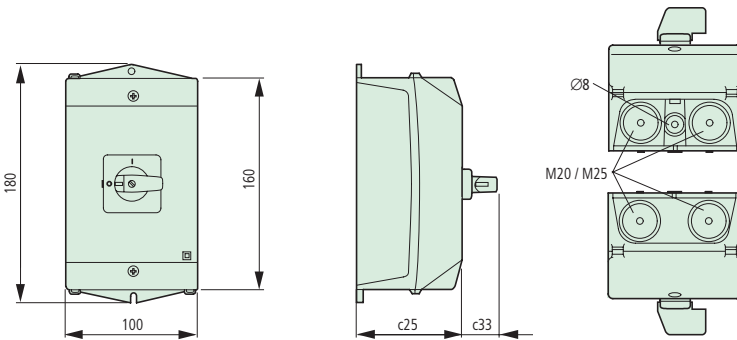


Drilling dimensions
Base

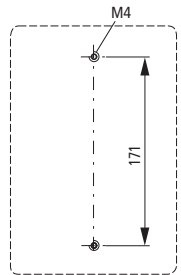


Surface mounting main switches


T0.../11/SVB

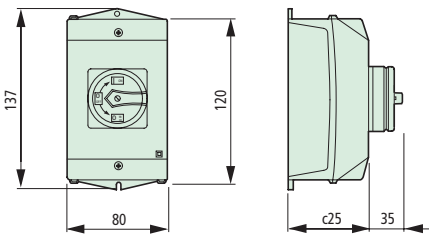



Drilling dimensions
Base

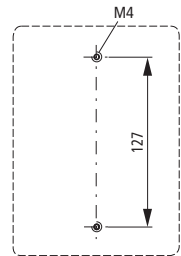

T3.../12/SVB

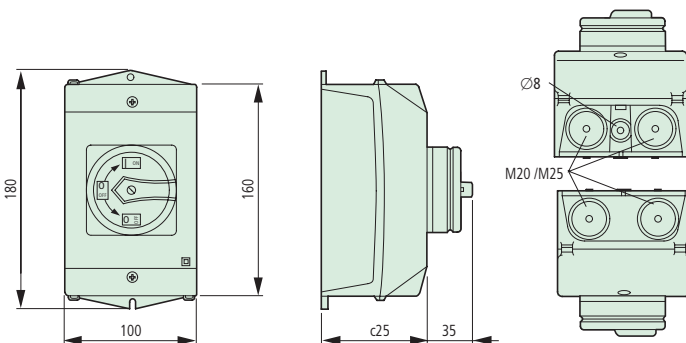

Drilling dimensions
Base

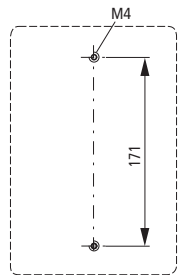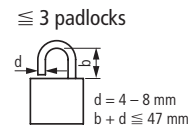

Type	c25
T0-1...	75
T0-2...	75
T0-3...	95
T0-4...	95


Type	c25	c33
T3-1...	80	27
T3-2...	80	27
T3-3...	100	35
T3-4...	100	35
T3-5...	145	35

T0, T3 Rotary Switches, P1, P3 Switch-Disconnectors, Accessories


Moeller HPL0211-2004/2005

Key operated lock mechanism


S-T0
S-SOND...-T0

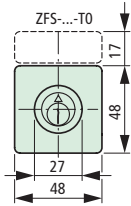






T0.../E(I1) + S-(SOND-)T0
T3.../E(I2) + S-(SOND-)T0

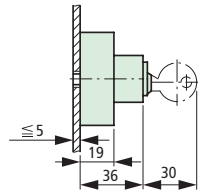

T0.../Z + S-(SOND-)T0
T3.../Z + S-(SOND-)T0

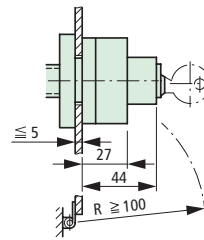


T0.../EZ Δ T0.../E + EZ-T0 + S-(SOND-)T0
T3.../EZ Δ T3.../E + EZ-T0 + S-(SOND-)T0

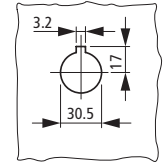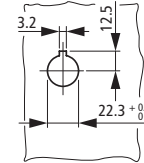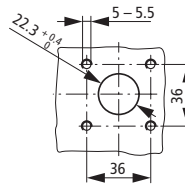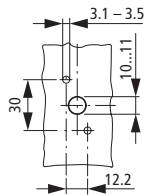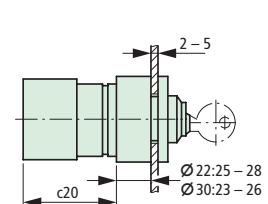


Cylinder lock


SVA-T3

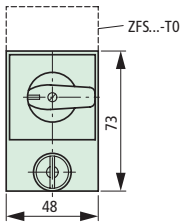


T0.../I1/SVA
T3.../I2/SVA
P1.../I2/SVA

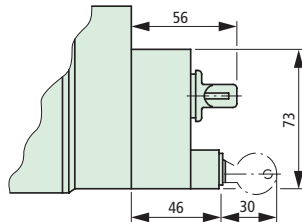


T0.../E/SVA...
T3.../E/SVA...
P1.../E/SVA

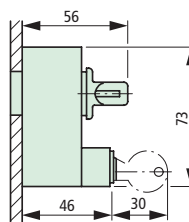


T0.../Z/SVA...
T3.../Z/SVA...
P1.../Z/SVA

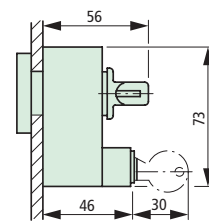


SVC-T3 padlocking feature

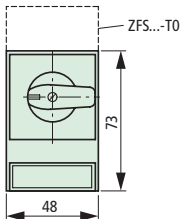


T0.../I1/SVC
T3.../I2/SVC
P1.../I2/SVC

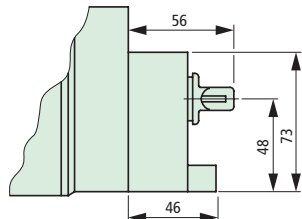

T0.../E/SVC...
T3.../E/SVC...
P1.../E/SVC



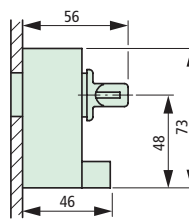


T0.../Z/SVC...
T3.../Z/SVC...
P1.../Z/SVC

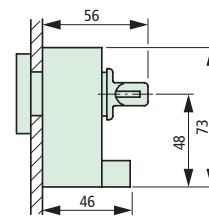


Modules

Switched neutral: N-P...
Auxiliary contacts: HI 11-P1/P3

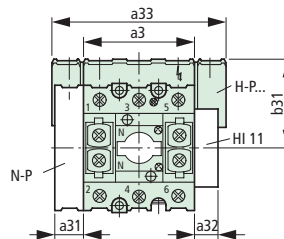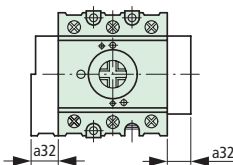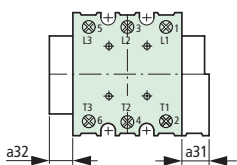

≅ 3 padlocks

 

Type	a3	a31	a32	a33	b31
P1-...	49	15	15	83	49
P3-..	72	18	15	114	60

