


Subminiature Rotary Coded Switches for SMT, waterproof

Specifications:


Contact rating:	switching: 150 mA, 42 V non-switching: 200 mA, 42 V
Contact resistance:	< 80 mΩ
Insulation resistance:	> 100 MΩ
Dielectric strength:	250 V, 50 Hz for the duration of 1 minute
Operating temperature:	-60 °C to +125 °C
Storage temperature:	-60 °C to +125 °C
Mechanical life:	minimum 10 000 operations
Terminals:	phosphor bronze, gold-plated over nickel barrier
Material:	case: PA6T grey meets UL 94 V-0 rotor: PA 66 grey, inverse type blue
Protection:	IP 67
Mounting:	on pc-board
Packing:	600 pcs/reel

Models: Code

SMR 60010	BCD
SMR 60110	BCD Inverse
SMR 60016	Hexadecimal
SMR 60116	Hexadecimal Inverse

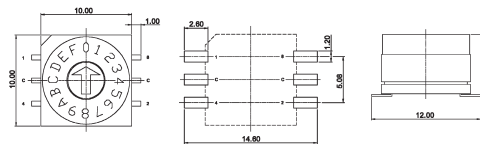

SMR 61010	BCD
SMR 61110	BCD Inverse
SMR 61016	Hexadecimal
SMR 61116	Hexadecimal Inverse

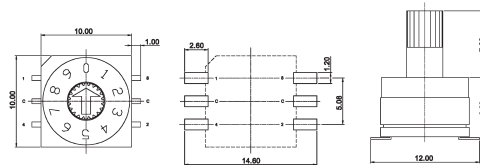

washable

