


Unless otherwise stated All Dimensions are in mm



General tolerance +/- 0.25mm

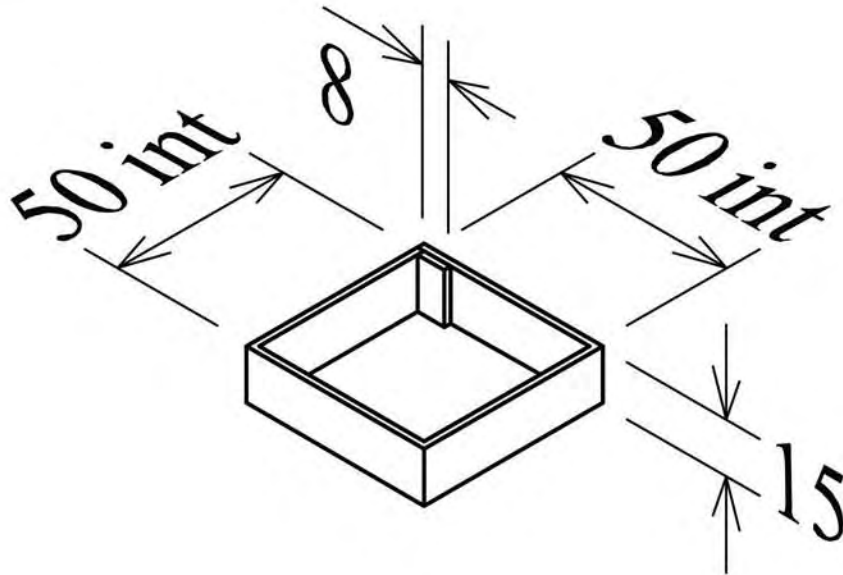

Part No. FFL1T

Issue	A	Date	30/03/2006
Drawn		Date	30/03/2006
Approved	P.J.H	Date	31/03/2006
Issue	B	Date	26/06/2006
Approved	P.J.H	Date	27/06/2006

Note:
Supplied complete with 2 fingered lid

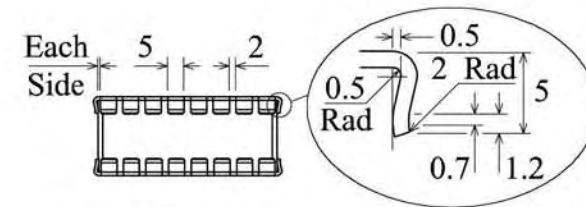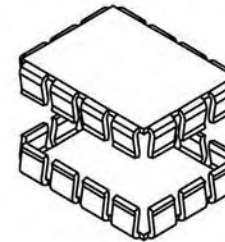

Specification:

Material: Bright Mild Steel BS EN 10130 DC01
Construction: Overlapped Spot Welded Frame
Frames & Cans: 20swg (0.914mm)
Lids: 24swg (0.559mm)
Finish: Bright Acid Tin - Good Commercial Grade
Surface Resistivity: $20 \times 10^{-6} \Omega$ per square
Conductivity: 5×10^4 mho

THIS DRAWING IS THE PROPERTY OF PERANCEA LTD AND MAY NOT BE COPIED OR REPRODUCED WITHOUT OUR WRITTEN CONSENT

PERANCEA LTD

ENCLOSURE AND INSTRUMENT CASE
DESIGNERS AND MANUFACTURERS

Unit 36, Silicon Business Centre, Greenford, UB6 7JZ

Telephone: 020 8365 2520

Fax: 020 8566 7217

Email: sales@perancea.com

Web: www.perancea.com