

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 27 ... 34 mm, WAF 50, screw connection: M40

Commercial data

| | |
|--------------------------------------|---------------------|
| Item number | 1607729 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | BF7 |
| Product key | AF7DAX |
| Catalog page | Page 690 (C-4-2015) |
| GTIN | 4017918938819 |
| Weight per piece (including packing) | 184.2 g |
| Weight per piece (excluding packing) | 168.65 g |
| Customs tariff number | 74198090 |
| Country of origin | DE |

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>

 


Technical data

Product properties

| | |
|------------------------------|-------------------|
| Product type | Cable screw gland |
| Application | Standard |
| No. of conductors | 1 |
| Type of the screw connection | M40 |
| Manufacturer | Jacob |
| Manufacturer Designation | 101036M40 |
| Shielded | no |

Dimensions

| | |
|---------------------------------|---|
| Dimensional drawing |  |
| Length | 35 mm |
| Length of the connecting thread | 8 mm |
| Hole diameter | 40.1 mm ... 40.3 mm |
| Wrench size, union nut | 50 mm |
| Wrench size, support | 50 mm |
| Hexagon angular dimension | 58 mm |
| Thread type connection side | M40 x 1.5 |
| Thread pitch | 1.5 mm |

Connection data

| | |
|-------------------|------------------------|
| Tightening torque | 20 Nm (Union nut) |
| | 20 Nm (Support sleeve) |

Material specifications

| | |
|-------------------------------|----------------------|
| Material Compression ring | PA |
| Seal material O-ring | NBR |
| Seal material Cable seal | Neoprene |
| Material for screw connection | Brass, nickel-plated |

Cable/line

| | |
|---------------------------------|-----------------|
| External cable diameter Cable 1 | 27 mm ... 34 mm |
| Halogen-free | no |

Environmental and real-life conditions

Ambient conditions

| | |
|----------------------|--------------------|
| Degree of protection | IP68 (up to 5 bar) |
|----------------------|--------------------|

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -30 °C ... 100 °C |
|---------------------------------|-------------------|

HC-M-KV-M40(27-34) - Cable gland


1607729

<https://www.phoenixcontact.com/in/products/1607729>



Drawings

Dimensional drawing

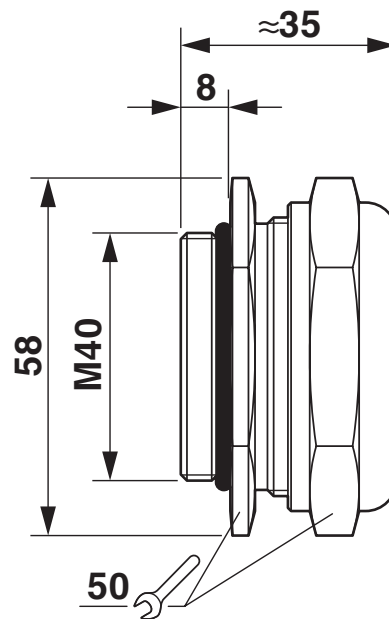

Dimensional drawing

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1607729>



EAC-RoHS

Approval ID: RU D-DE.HB35.B.00387

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-11.0 | 27144432 |
| ECLASS-12.0 | 27140801 |
| ECLASS-13.0 | 27140801 |

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC000441 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121300 |
|-------------|----------|

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



Environmental product compliance

EU RoHS

| | |
|---|------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(c) |

China RoHS

| | |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50 |
| | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | fb259922-836a-4076-b45a-ad83019743f0 |

HC-M-KV-M40(27-34) - Cable gland

1607729

<https://www.phoenixcontact.com/in/products/1607729>



Accessories

A-INL-M40-N-S - Counter nut

1411246

<https://www.phoenixcontact.com/in/products/1411246>

Counter nut, for threads M40 x 1.5, color: silver



SEALING PLUG 25X30 RD - Sealing plug

1421863

<https://www.phoenixcontact.com/in/products/1421863>

Sealing plug, color: red



Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in