



EN

Datasheet

RS PRO NYLON-HEAT SHRINKABLE-BUTT SPLICE CONNECTORS “HT” (TUBULAR TYPE)

Stock number: 178-7185

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16	14
AMP.	18	30

MAXIMUM ELECTRICAL RATING: 600 VOLTS MAX.


SHRINK TEMP. : 180° C

OPERATING TEMP. : -55° C~+105° C

INSULATION MATERIAL: NYLON

TERMINAL MATERIAL: COPPER TUBULAR

INSULATION COLOR: BLUE

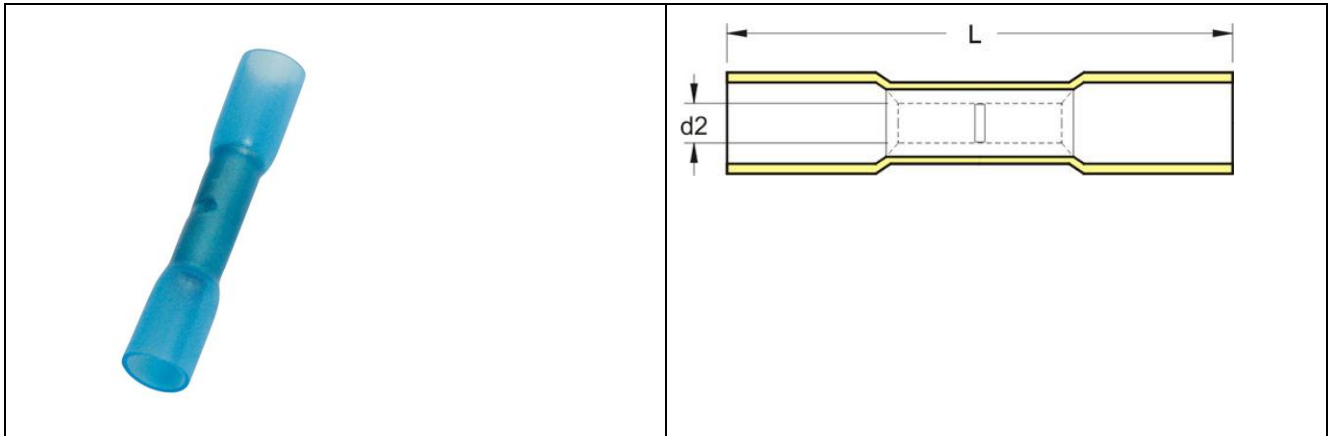

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION inch(mm)	
		d2	L
16-14 A.W.G. 1.5-2.5 mm ²	178-7185	0.091 2.300	1.417 36