

Previously known as: Hylite™



Oil



Medium Duty

Three quarter-dipped nitrile-coated work gloves, for mechanical resistance, flexibility and comfort

- **Optimized comfort and ergonomics:** With a design shaped to natural hand contours, interlock knit lining, and generous sizing, ActivArm® Hylite™ 47-400 three quarter-dipped nitrile-coated work gloves offer superb comfort
- **Advanced protection:** These industrial gloves' special nitrile formulation combines strong mechanical protection, abrasion resistance and oil repellency with high levels of flexibility
- **Enhanced durability:** They outwear cotton alternatives by a margin of 12 to 1, light leather gloves by 5 to 1 and PVC-coated gloves by 3 to 1
- **Reduced surface defect risks:** Containing no silicone, these robust ActivArm® gloves are ideal for metal sheet handling and motor manufacture, with assured cleanliness and minimal risks of contaminant transfer



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication

Applications


- Handling metal sheets & panels
- Chassis assembly, body trimming
- Final assembly
- Inspection (picking, checking and marking)
- Cutting glasses, sheets, panels
- Fabricating metal parts, glass sheets
- Assembly & inspection of components

Previously known as: Hylite™

Key Features

- **Contoured design with interlock knit lining:** Optimal comfort and ergonomics
- **Nitrile formulation:** Oil repellency, flexibility and abrasion resistance
- **Silicone-free design:** Clean, contaminant-free metal handling

Performance Standards & Regulatory Compliance

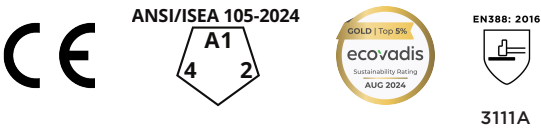

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COATING COLOR	PACKAGE
ActivArm® Hylite™ 47-400	Finishing: ¾ Dipped Coating Material: Nitrile Liner Material: Interlock cotton Cuff Style: Knitwrist	N/A	7, 8, 9, 10	265-295 mm; 10.74-11.37 inches	Blue	12 pairs/bag, 12 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 900
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

