



Multi Purpose



Light Duty

Lightweight industrial gloves that blend dexterity and sensitivity for delicate handling

- **Heightened tactility:** HyFlex® 11-605 polyurethane gloves boast high tactile sensitivity, thanks to a number of characteristics, including finger-dipped polyurethane coating
- **Greater choice:** While these HyFlex® gloves are finger-dipped, enhancing their tactile sensitivity, near-identical HyFlex® 11-600 and 11-601 models are palm-dipped, for added protection
- **Augmented dexterity:** HyFlex® 11-605 safety gloves are also lightweight, flexible and dexterous, making them ideal for the precise handling of small, delicate components
- **Elevated comfort:** Designed with a knitwrist cuff, they ensure reduced hand fatigue and enhanced comfort
- **Improved durability:** The HyFlex® 11-605 model satisfies ANSI/ISEA 105-2024 ABRASION LEVEL 1 standards, for longer wear



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication

Applications

- Assembly & inspection of components
- Assembling and mounting components
- Adjusting systems and screwing

Key Features


- Finger-dipped: Maximum tactility for perfect precision handling
- PU coating and nylon liner: For added lightness and dexterity
- Light color: PPE gloves suited to less dirt-prone applications

Vulcanization Chemical Accelerators

- Natural rubber proteins

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

Performance Standards & Regulatory Compliance

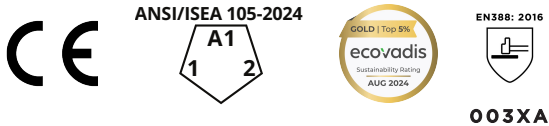

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COATING COLOR	PACKAGE
HyFlex® 11-605	Finishing: Uncoated, Fingertip dipped Coating Material: Polyurethane Liner Material: Nylon Cuff Style: Knitwrist	15	6, 7, 8, 9	195-230 mm 7.67-9.05 inches	White	12 pairs/bag, 12 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

North America Region
Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 900
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Canada
Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Australia
Ansell Limited
Level 3, 678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region
Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.