

IPD PL 5P2,5 M GY - Connector



1088676

<https://www.phoenixcontact.com/in/products/1088676>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Connector, product family: IPD, connection method: Push-lock connection, number of positions: 4+PE, Pin, 0.5 mm² ... 2.5 mm², 600 V, 17.5 A, PA, light gray, coding: P, external cable diameter: 7 mm ... 11 mm and 11 mm ... 16 mm

Your advantages

- Easy distribution of power, as components are plugged directly
- Simple, time-saving wiring in the field with Push-Lock connection
- Reliable installation in harsh environments with IP66, IP68, and IP69K throughout the entire system
- Secure, tool-free locking even in particularly difficult installation situations
- Fast commissioning with preassembled cable assemblies

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1088676 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Product key | AF6JCA |
| GTIN | 4055626890937 |
| Weight per piece (including packing) | 78.5 g |
| Weight per piece (excluding packing) | 22.22 g |
| Country of origin | DE |

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



Technical data

Notes

| | |
|---------|---|
| General | NOTE: Observe the permissible bending radii when routing cables, since the degree of protection may be at risk if the bending forces are too high. Reduce mechanical loads upstream of the connector, e.g., by using cable ties. |
|---------|---|

Product properties

| | |
|------------------------------------|------------------------|
| Product type | Installation connector |
| Product family | IPD |
| Number of positions | 5 |
| Connection profile | 4+PE |
| Position marking | 1, 2, 3, N, PE |
| Number of connections per position | 1 |
| Coding | P |

Insulation characteristics

| | |
|----------------------|-----|
| Overvoltage category | III |
| Degree of pollution | 3 |

Electrical properties

| | |
|-----------------------------|----------------------|
| Rated surge voltage (III/3) | 6 kV |
| Rated current | 17.5 A |
| Rated voltage (III/3) | 600 V |
| Nominal voltage U_N | 600 V AC 600 V DC |
| Nominal current I_N | 17.5 A |

Connection data

Connection technology

| | |
|-------------------------------------|----------------------|
| Connection method On the field side | Push-lock connection |
|-------------------------------------|----------------------|

Conductor connection

| | |
|--------------------------------------|---|
| Conductor cross section flexibel | 0.5 mm ² ... 2.5 mm ² |
| Conductor cross section solid | 0.5 mm ² ... 2.5 mm ² |
| Conductor cross section with ferrule | 0.5 mm ² ... 2.5 mm ² |
| Connection cross section AWG | 20 ... 14 |

Dimensions

| | |
|---------------------|--|
| Dimensional drawing | |
|---------------------|--|

IPD PL 5P2,5 M GY - Connector



1088676

<https://www.phoenixcontact.com/in/products/1088676>

| | |
|--------|---------|
| Width | 32.5 mm |
| Height | 32.1 mm |
| Length | 91.7 mm |

Material specifications

| | |
|--|-----------------------|
| Color (Housing) | light gray (RAL 7035) |
| Material Housing | PA |
| Material Seal | NBR |
| Flammability rating according to UL 94 | V0 |
| Contact material | Cu |
| Contact surface material | Ni/Ag/Sn |

Cable/line

| | |
|-------------------------|-----------------|
| External cable diameter | 7 mm ... 11 mm |
| | 11 mm ... 16 mm |
| Position marking | 1, 2, 3, N, PE |

Mechanical properties

Mechanical data

| | |
|-----------------------------|----------------------|
| Insertion/withdrawal cycles | 50 (IP66/IP68/IP69K) |
| | 100 (IP66) |


Environmental and real-life conditions

Ambient conditions

| | |
|---|--|
| Degree of protection | IP66 |
| | IP68 (2 m / 24 h) |
| | IP69K |
| | Touch-proof when not plugged in (IP2X) |
| Impact strength | IK07 |
| Ambient temperature (operation) | -30 °C ... 100 °C |
| Temperature when conductor connected | -5 °C ... 50 °C |
| Ambient temperature (storage/transport) | -30 °C ... 100 °C |
| Resistance to UV radiation | yes |


Drawings

Diagram

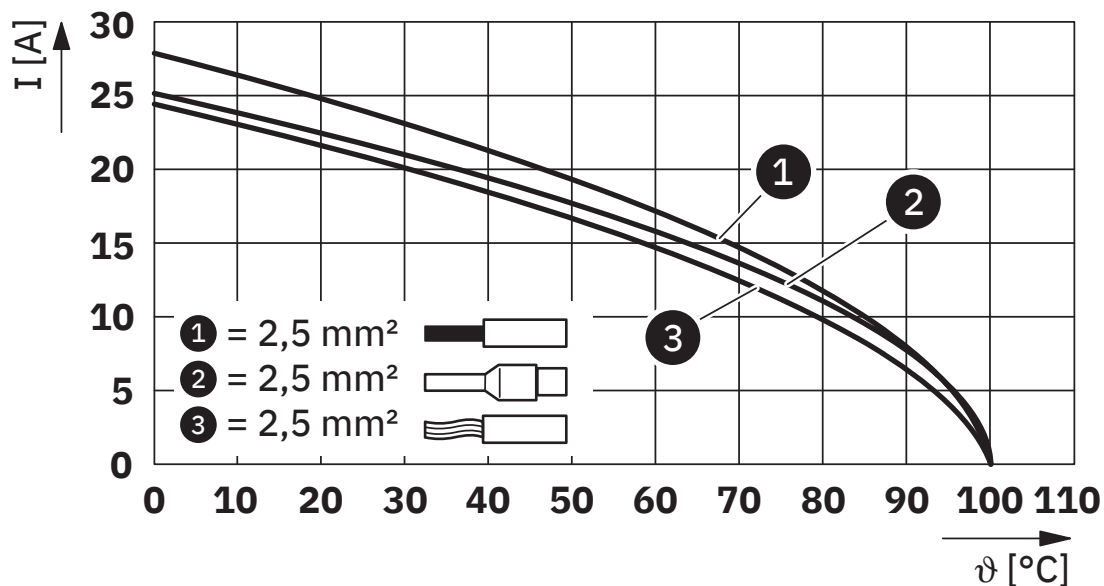

Derating diagram for 2.5 mm²

Diagram

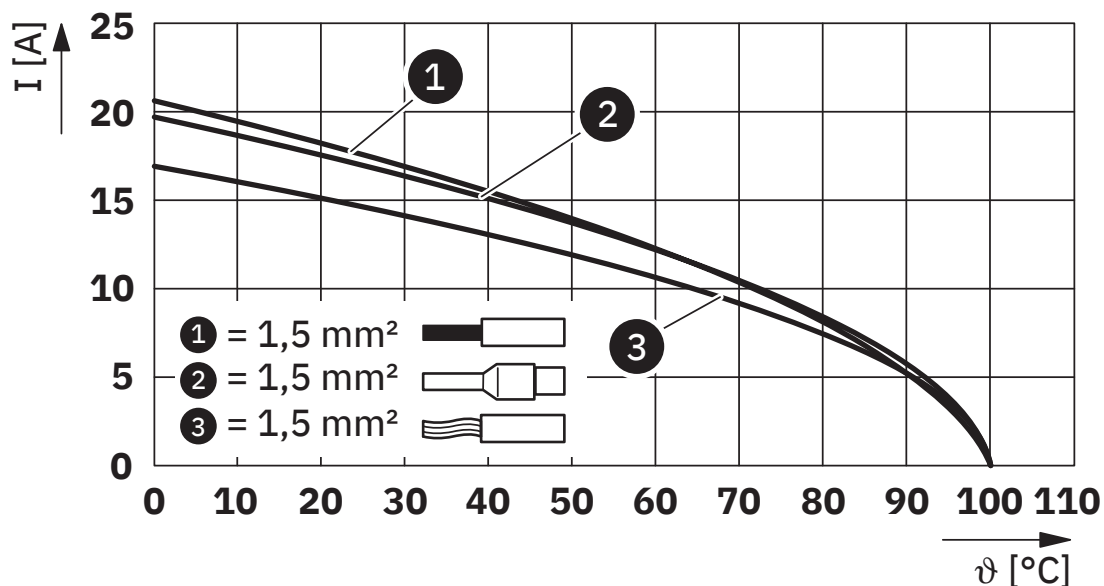

Derating diagram for 1.5 mm²


IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>




Diagram

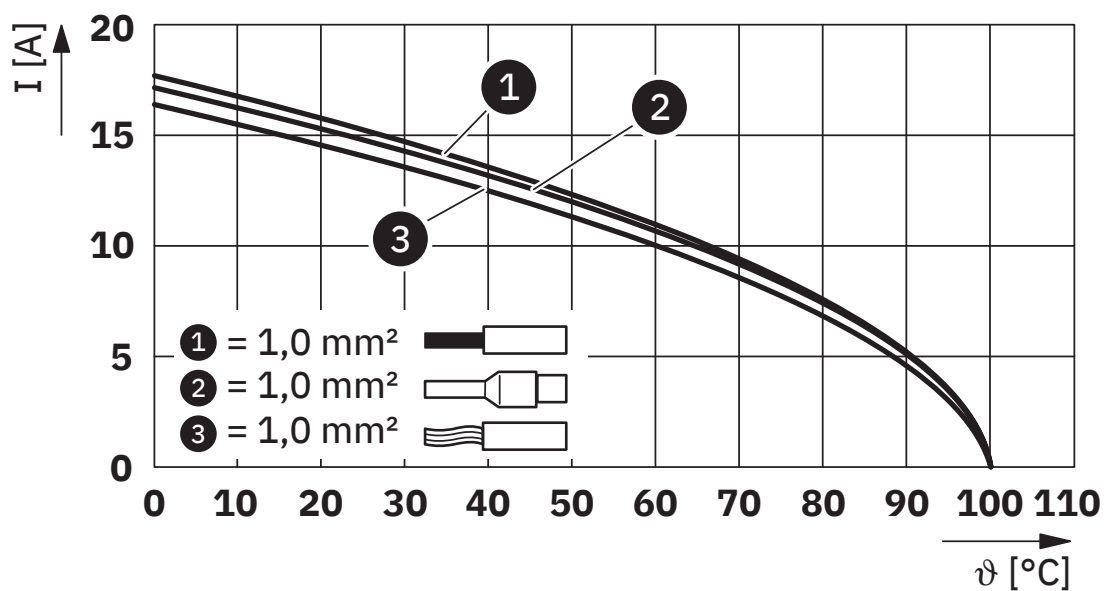

Derating diagram for 1.0 mm²

Dimensional drawing

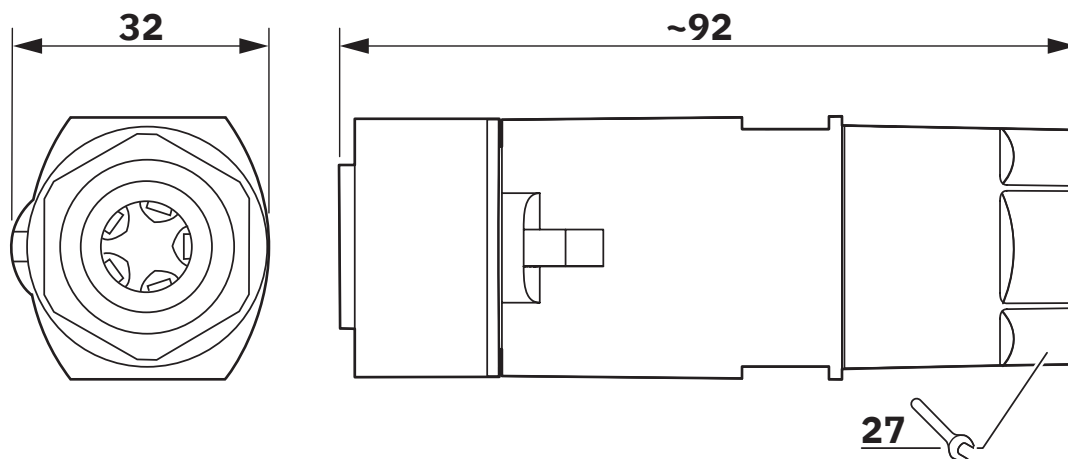

IPD PL 5P2,5 M GY - Connector


1088676


<https://www.phoenixcontact.com/in/products/1088676>



Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1088676>

**VDE Zeichengenehmigung**
Approval ID: 40059408

| | | | | |
|---|---|-----------------------|-------------------|-----------------------------|
|  | cULus Listed Approval ID: E468743 | | | |
| | Nominal voltage U_N | Nominal current I_N | Cross section AWG | Cross section mm^2 |
| Only rigid conductors | 600 V | 20 A | - 14 | - |
| multi-stranded with ferrule | 600 V | 20 A | - 14 | - |

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-11.0 | 27440605 |
| ECLASS-12.0 | 27440605 |
| ECLASS-13.0 | 27440605 |

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC002560 |
|----------|----------|

IPD PL 5P2,5 M GY - Connector



1088676

<https://www.phoenixcontact.com/in/products/1088676>

Environmental product compliance

| | |
|---|--|
| EU RoHS | |
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
| China RoHS | |
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |
| EU REACH SVHC | |
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



Mandatory accessories

IPD P 5P2,5 F GY - Connector

1088677

<https://www.phoenixcontact.com/in/products/1088677>



Connector, product family: IPD, connection method: Push-lock connection, number of positions: 4+PE, Socket, 0.5 mm² ... 2.5 mm², 600 V, 17.5 A, PA, light gray, coding: P, external cable diameter: 7 mm ... 11 mm and 11 mm ... 16 mm

IPD W 5P2,5 F M25 GY - Panel feed-through

1088692

<https://www.phoenixcontact.com/in/products/1088692>



Panel feed-through, for connectors, product family: IPD, connection method: Push-in connection, number of positions: 4+PE, M25, Socket, 0.5 mm² ... 2.5 mm², 600 V, 17.5 A, PA, gray, coding: P

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



IPD W 5P2,5 F 0,5 M25 GY - Panel feed-through

1088705

<https://www.phoenixcontact.com/in/products/1088705>



Panel feed-through, for connectors, product family: IPD, connection method: Single wires, number of positions: 4+PE, M25, Socket, 450 V, 17.5 A, PA, gray, coding: P, 2.5 mm², cable length: 0.5 m

IPD Y 5P2,5 BK - Y distributor

1499533

<https://www.phoenixcontact.com/in/products/1499533>



Y distributor, product family: IPD, number of positions: 4+PE, 600 V, 17.5 A, black, coding: P

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



IPD H 5P2,5 BK - H distributor

1499531

<https://www.phoenixcontact.com/in/products/1499531>

H distributor, product family: IPD, number of positions: 4+PE, 600 V, 17.5 A, black, coding: P



IPD P 5P2,5 F A1,0 PVC GY - Connecting cable

1692858

<https://www.phoenixcontact.com/in/products/1692858>



Connecting cable, product family: IPD, connection method: Push-lock connection, number of positions: 4+PE, Socket, 0.5 mm² ... 2.5 mm², 450 V, 16 A, PA, light gray, coding: P, 2.5 mm², cable length: 1 m, Socket straight, on free cable end

Accessories

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



SEALING PLUG 10X16 RD - Sealing plug

1400284

<https://www.phoenixcontact.com/in/products/1400284>

Sealing plug, for threads pluggable, color: red



SEALING PLUG 14X22 RD - Sealing plug

1400270

<https://www.phoenixcontact.com/in/products/1400270>

Sealing plug, for threads pluggable, color: red



IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



ZBF 4:UNBEDRUCKT - Zack Marker strip, flat

0808587

<https://www.phoenixcontact.com/in/products/0808587>




Zack Marker strip, flat, Strip, white, unlabeled, can be labeled with: CMS-P1-PLOTTER, PLOTMARK, mounting type: latching, for terminal block width: 4 mm, Number of individual labels: 10, text field height: 5.2 mm, text field width: 4.2 mm

UC-TMF 4 - Marker for terminal blocks

0818166

<https://www.phoenixcontact.com/in/products/0818166>

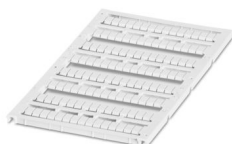

Marker for terminal blocks, Sheet, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: latching, for terminal block width: 4.2 mm, Number of individual labels: 120, text field height: 5.1 mm, text field width: 3.6 mm

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



UCT-TMF 4 - Marker for terminal blocks

0828742

<https://www.phoenixcontact.com/in/products/0828742>



Marker for terminal blocks, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: latching, for terminal block width: 4.2 mm, Number of individual labels: 90, text field height: 4.7 mm, text field width: 3.4 mm

IPD CAP W32 WP GY - Protective cap

1088710

<https://www.phoenixcontact.com/in/products/1088710>



Protective cap, IPD, without locking element, IP66, IP68, IP69K, width: 32 mm, color: gray, for IPD PL 5P2,5...

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



IPD SEAL W32 2XASI - Seal

1698173

<https://www.phoenixcontact.com/in/products/1698173>



Seal, for connectors, product family: IPD, black, For IPD ... 5P2,5 ..., For IPD ... 5F2,5 ...

IPD SEAL W32 1XASI - Seal

1698174

<https://www.phoenixcontact.com/in/products/1698174>



Seal, for connectors, product family: IPD, black, For IPD ... 5P2,5 ..., For IPD ... 5F2,5 ...

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



QSS 27 - Socket wrench

1670646

<https://www.phoenixcontact.com/in/products/1670646>



Allen wrench, for loosening and fastening the QUICKON union nut, WAF 27 mm

SZF 1-0,6X3,5 - Screwdriver

1204517

<https://www.phoenixcontact.com/in/products/1204517>



Actuation tool, for ST terminal blocks, also suitable for use as a bladed screwdriver, size: 0.6 x 3.5 x 100 mm, 2-component grip, with non-slip grip

IPD PL 5P2,5 M GY - Connector

1088676

<https://www.phoenixcontact.com/in/products/1088676>



CRIMPFOX VARIO 4S - Crimping pliers

1108766

<https://www.phoenixcontact.com/in/products/1108766>



Crimping pliers, contact connection type: Insulated and uninsulated ferrules, min. cross section: 0.25 mm², max. cross section: 4 mm², compression: Square crimp, weight 401 g, black/green

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in