

## Housing - HC-HPR-B16-BFH-EMR-BK - 1411060

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B16 panel mounting base, HPR series, for screw locking, for increased environmental and EMC requirements



### Key commercial data

Packing unit	1 pc
GTIN	 4 046356 921619
Weight per Piece (excluding packing)	22.22 g
Custom tariff number	85389099
Country of origin	China

### Technical data

#### Dimensions

Height	20 mm
Width	58 mm
Length	165 mm
Length of the assembly cutout	82 mm
Width of the assembly cutout	35 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP68 (0.5 bar, 24 h)
	IP69K
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Note	For contact inserts HC-B16, BB32, D40, DD72, HS6, M, K
Type	B16
Housing type	Panel mounting base

# Housing - HC-HPR-B16-BFH-EMR-BK - 1411060

## Technical data

### General

Locking type	for M6 screws
Torque	4 Nm (Locking screw)
Screw connection	none
Housing material	Aluminum die-cast
Housing surface material	Powder-coated, black
Seal material	NBR
Material lock	High-grade steel
Material of locking screw	High-grade steel

## Classifications

### eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261203
eCl@ss 8.0	27440202

### ETIM

ETIM 4.0	EC000437
ETIM 5.0	EC000437

## Approvals

### Approvals

---

Approvals

EAC / GL

---

Ex Approvals

---

Approvals submitted

---

### Approval details

 
EAC
-----

GL
----


## Drawings

# Housing - HC-HPR-B16-BFH-EMR-BK - 1411060

Dimensioned drawing



Dimensioned drawing

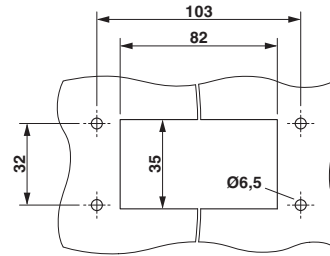

Dimensional drawing

Panel cutout