



GE
Lighting

23
kWh/1000h

A+
energy class

93
lumens/watt

T5 LongLast™ - High Efficiency, G5 Cap

FT5/21W/865/GE/LL/SL1/30

61094




Product information

T5 LongLast™ lamps are triphosphor fluorescent lamps with 16mm outer diameter (5/8 of an inch). These lamps feature “Starcoat™ Technology” that delivers high quality triphosphor performance. GE produces two ranges of T5 LongLast™ lamps in 4 different lengths:

- High Efficiency offering high lumens per watt
- High Output offering improved lumen package

Application areas

- Retail
- Office
- Education
- Industrial

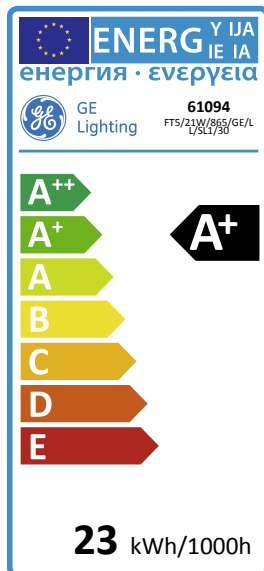

WORLDWIDE PARTNER

Product data

Product Code	61094
Bulb Shape	Tubular
Bulb Diameter [mm]	16
Regulatory comment	EUP related
Bulb maximum overall diameter [mm]	16
Cap to Cap Length (Max) [mm]	849
Net weight per piece [g]	77
Gross weight per piece [g]	100
Mercury Content [mg]	2.5
UV radiance	Exempt
Brand	General Electric (GE)
Cap/Base	G5

Performance data

Colour Code	865
Lumen at 25°C [lm]	1770
Weighted energy consumption [kWh/1000h]	22.57
Rated efficacy [lm/W]	94
Energy efficiency class (EEC)	A+
Rated Life [h]	30000
Rated median life on electronic (HF / ECG) ballast on IEC 36000 12-hour cycle	
Rated median life on electronic (HF / ECG) ballast on IEC 30000 3-hour cycle	
Nominal correlated colour temperature (CCT) [K]	6400
Nominal lumens [lm]	1950
Colour Rendering Index (CRI) [Ra]	85


Electrical data

Design Ambient Temperature [°C]	35
Design Lamp ambient temperature [°C]	35
Starting ambient temperature range	-15
Dimming Capability	Yes
Nominal power [W]	21


Logistic data

DUN Code	10043168610947
EAN Code	0043168902519
Pack Quantity	30
Inner pack type	SLEEVE
Outer pack type	OUTER BOX
Layer quantity	180 EUR, 300 UK
Layer quantity EUR	180
Layer quantity UK	300
Pallet quantity EUR (PC)	1800
Pallet quantity UK (PC)	3000
Outer case size	890 x 120 x 102 (mm)
Product status	Available


Technical drawing

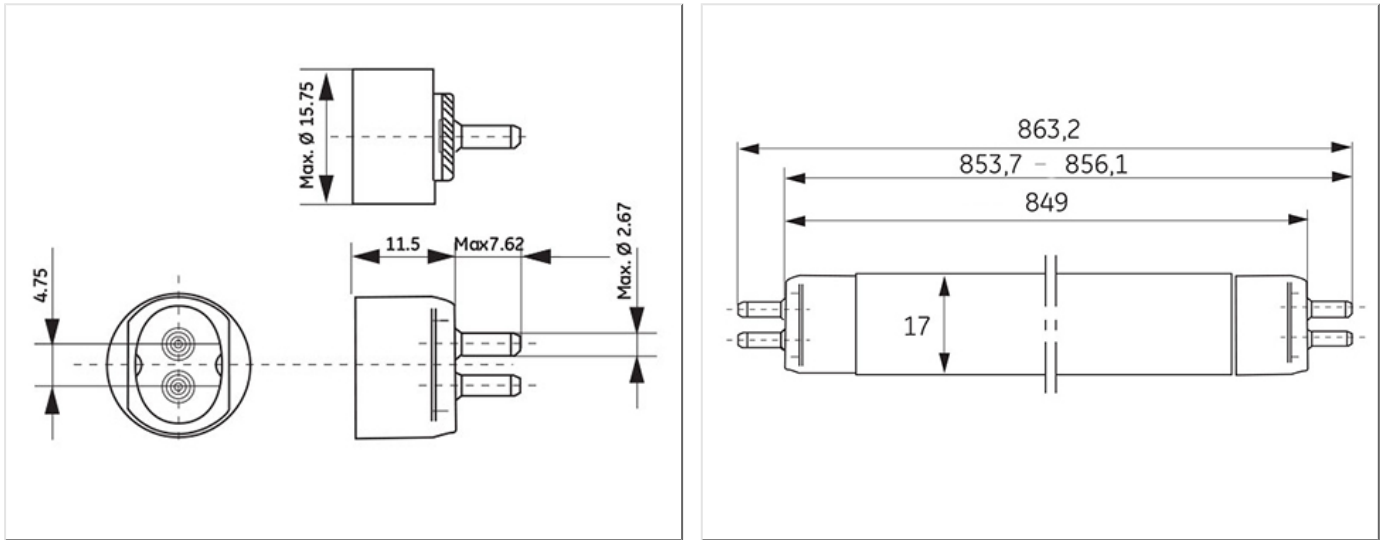


Lumen maintenance data

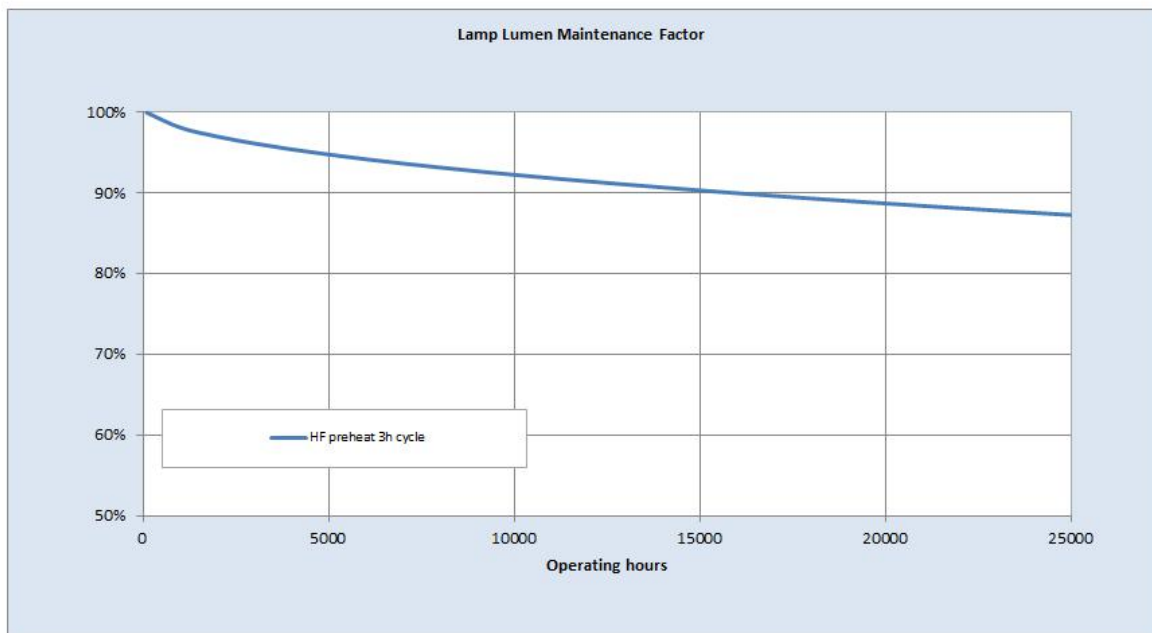

Survival data

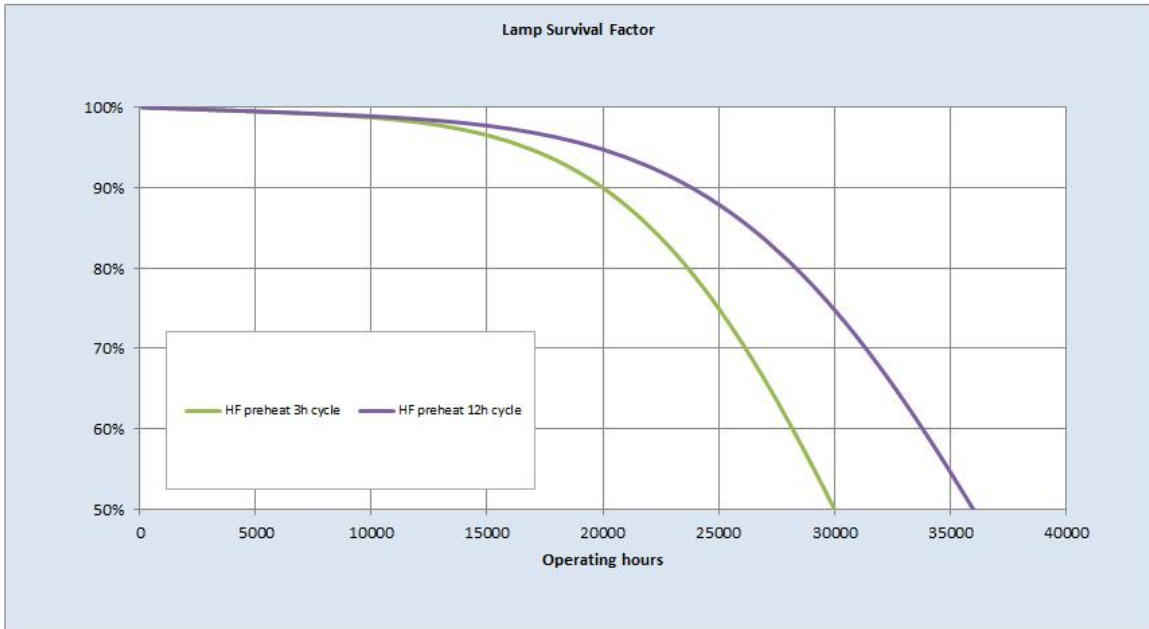

Service life data

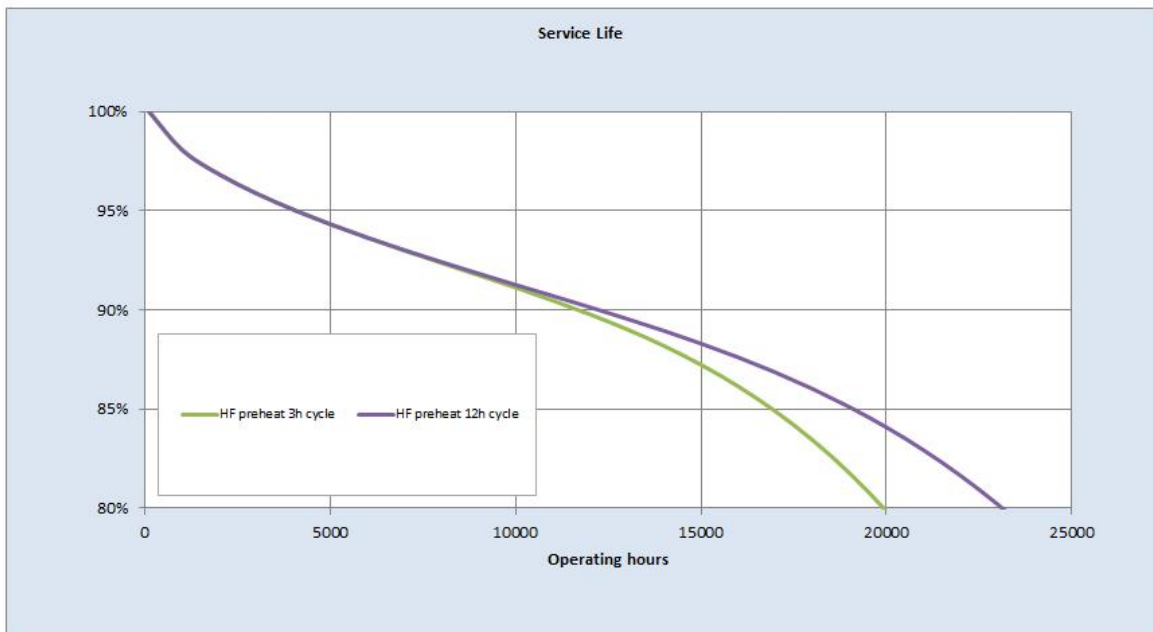

Downloads & Links

[Go to the catalog site \(HTTP\)](#)

[Linear Fluorescent Lamps Catalogue \(PDF\)](#)

[LFL T5 LongLast™ Lamps - Data sheet \(EN\) \(PDF\)](#)

[Lighting design tools & calculators \(HTTP\)](#)

[High-res images / Technical drawings \(HTTP\)](#)

[Certificate for the Quality Management System of GE Lighting EMEA \(PDF\)](#)

[Certificate for the Environmental Management System of GE Lighting EMEA \(PDF\)](#)

Disclaimer

Lumen maintenance may vary for lamps with colour temperature $\geq 5000\text{K}$