




LED Spot PAR16 Black GU10 DIM 6W (65W) 450lm 940 38°

Article number: 146228

BAI BaiSpot Black LED PAR16 GU10 4000K 6W (65W) 450lm 38° Dimmable CRI90 230V-240V 50x53mm Reflector LED-lamp

These BaiSpot Black reflector LED lamps are distinguished not only by their stylish black housing, but also by the high CRI value of 90. So twice as beautiful. The housing is so stylish that these light sources can be used in an open fixture perfectly. This version of the BaiSpot is dimmable. Make sure you use the correct LED dimmer. Ambient temperature range: -25°C to +40°C.

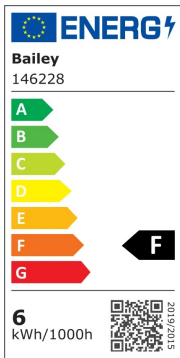

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Spot PAR16 Black GU10 DIM 6W (65W) 450lm 940 38°
Brand	Bailey
Productseries	BaiSpot LED MV
Producttype	GU10 Black

ETIM specifications

Socket	GU10
Luminous flux [lm]	450 - 450
Nominal voltage [V]	220 - 240
Lamp power [W]	6 - 6
Colour temperature [K]	4000 - 4000
Diameter [mm]	50
Length [mm]	53
Dimmable	Yes
Lamp shape	Reflector
Beam angle [°]	38 - 38
Colour	White
Type of glass/cover	Prism
Lamp designation	PAR16
Colour rendering index CRI	90-100
Voltage type	AC
Filament lamp	No
Luminous intensity [cd]	850
Rated luminous flux according to IEC 62612 [lm]	450
Power factor	0.5
Lamp efficacy [lm/W]	75
Nominal current [mA]	33 - 33
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Housing colour	Black
Average nominal lifetime [h]	25000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	12500
Weighted energy consumption in 1000 hours [kWh]	6
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No

Dimming Zigbee	No
Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No

Complementary articles



141201
Textile Cable 3C 3M Brown



141234
Lampholder GU10 2A 250V
T250°C Side 150mm