


Geberit Mapress Stainless Steel adaptor union with male thread, union nut made of CrNi steel

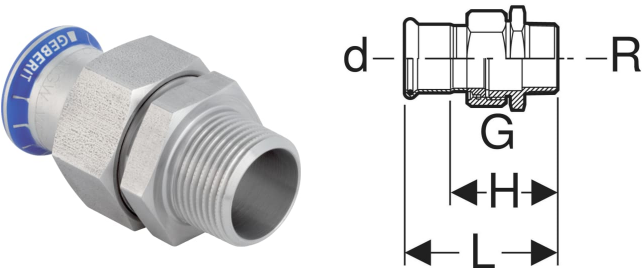

Example image

APPLICATION PURPOSES

- For cold and hot potable water
 - For cooling and heating water without antifreeze agent
 - For cooling and heating water with antifreeze agent
 - For district heating water ≤ 120 °C
 - For saturated steam ≤ 120 °C
 - For service water and process water
 - For treated water
 - For rainwater with a pH value ≥ 5.5
 - For grey and black water with a pH value ≥ 5.5
 - For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
 - For sprinklers (wet)
 - For chemicals and technical liquids
 - For compressed air (oil purity class 0–3)
 - For negative pressure
 - For inert gases (e.g. nitrogen)
 - For industrial gases (e.g. acetylene, shielding gases)
 - For technical building systems, industry and shipbuilding

- Leaky if unpressed
- Seal ring made of CIIR, black
- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	CrNiMo steel 1.4401 (EN 10088)

CHARACTERISTICS

- Pressing indicator

Art. no.	DN	d, ø mm	R "	G "	L cm	H cm
35360	12 / 15	15	1/2	3/4	6.4	4.4
35361	12 / 20	15	3/4	3/4	6.6	4.6

Art. no.	DN	d _ø mm	R "	G "	L cm	H cm
35362	15	18	1/2	3/4	6.4	4.4
35363	15 / 20	18	3/4	3/4	6.6	4.6
35364	20 / 15	22	1/2	1	6.7	4.6
35365	20	22	3/4	1	6.8	4.7
35366	20 / 25	22	1	1	7.3	5.2
35367	25	28	1	1 1/4	7.8	5.5
35368	32	35	1 1/4	1 1/2	8.5	5.9
35369	40	42	1 1/2	1 3/4	9	6
35370	50	54	2	2 3/8	10.3	6.8