


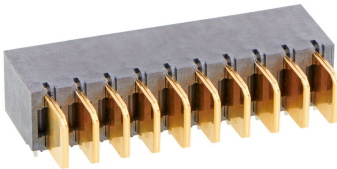

**Part Number :** [2195620032](#)  
**Product Description :** EXTreme Guardian HD  
Right-Angle Plug Assembly without Guide  
Pins, 2 Power Circuits  
**Series Number :** 219562  
**Status :** Active  
**Product Category :** Board-to-Board  
Connectors



## Documents & Resources

**Drawings**  
[2195620032\\_sd.pdf](#)

**3D Models and Design Files**  
[2195620032\\_stp.zip](#)

**Specifications**  
[2141130000-PS-000.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Low-Halogen per                                                                       |
| REACH SVHC         | Not Contained per D(2024)6225-DC<br>(07 Nov 2024)                                     |
| EU RoHS            | Compliant per                                                                         |

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|                |                                                                                    |
|----------------|------------------------------------------------------------------------------------|
| Status         | Active                                                                             |
| Category       | Board-to-Board Connectors                                                          |
| Series         | 219562                                                                             |
| Description    | EXTreme Guardian HD Right-Angle Plug Assembly without Guide Pins, 2 Power Circuits |
| Application    | Board-to-Board, Power                                                              |
| Component Type | PCB Header                                                                         |
| Product Name   | EXTreme Guardian HD                                                                |
| UPC            | 196823042638                                                                       |

#### Agency

|     |         |
|-----|---------|
| CSA | LR19980 |
| UL  | E29179  |

#### Electrical

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 130.0A |
| Voltage - Maximum             | 125V   |

#### Physical

|                                |       |
|--------------------------------|-------|
| Breakaway                      | No    |
| Circuits (Loaded)              | 2     |
| Circuits (maximum)             | 2     |
| Color - Resin                  | Black |
| Durability (mating cycles max) | 200   |
| First Mate / Last Break        | No    |
| Flammability                   | 94V-0 |
| Glow-Wire Capable              | No    |
| Guide to Mating Part           | No    |

|                                |                              |
|--------------------------------|------------------------------|
| Keying to Mating Part          | None                         |
| Lock to Mating Part            | None                         |
| Mated Height                   | 12.74mm                      |
| Material - Metal               | High Conductivity Copper     |
| Material - Plating Mating      | Gold                         |
| Material - Plating Termination | Tin                          |
| Material - Resin               | Liquid Crystal Polymer       |
| Net Weight                     | 8.906/g                      |
| Number of Rows                 | 1                            |
| Orientation                    | Right Angle                  |
| Packaging Type                 | Tray                         |
| PC Tail Length                 | 3.30mm                       |
| PCB Locator                    | No                           |
| PCB Retention                  | None                         |
| PCB Thickness - Recommended    | 1.58mm                       |
| Pitch - Mating Interface       | 5.78mm                       |
| Plating min - Mating           | 0.762µm                      |
| Plating min - Termination      | 2.540µm                      |
| Polarized to Mating Part       | Yes                          |
| Polarized to PCB               | Yes                          |
| (p)ower-(s)ignal Configuration | 2p - 0s                      |
| Temperature Range - Operating  | -40° to +125°C               |
| Termination Interface Style    | Through Hole - Compliant Pin |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                   | Part Number       |
|-----------------------------------------------------------------------------------------------|-------------------|
| EXTreme Guardian HD Vertical Receptacle Assembly without Guide Receivers, 2 Power Circuits    | <u>2195630032</u> |
| EXTreme Guardian HD Right-Angle Receptacle Assembly without Guide Receivers, 2 Power Circuits | <u>2195640032</u> |

---



---

This document was generated on Feb 02, 2025