

HONEYWELL H910 PLUS DISPOSABLE RESPIRATOR

N95 Particulate Respirators

Honeywell is introducing H910 Plus, designed to offer N95 level of respiratory protection against non-oil particles. It comes in a larger size to provide a better breathing space inside. Its soft foam minimizes the pressure on the nose bridge and the advanced anti-counterfeit filter media offers greater air permeability, comfort and a secure seal.



FEATURES AND BENEFITS

- Prevents non-oil particles and offers filtering efficiency that exceeds 95%.
- Comes with Honeywell's anti-counterfeiting filter material that blocks fine particles.
- The nose clip is made of a high-strength plastic composite metal that provides enhanced bending resistance capacity, better fit and improved protection without metal exposure.
- The advanced sealing material used for the nose pad offers excellent fit, softness and comfort, relieving the nose bridge's pressure.
- Its large size provides ample breathing space inside for greater comfort.
- The latex-free elastic head straps reduce the pressure on the head, providing more comfort for long time use.

ORDERING INFORMATION

SKU	DESCRIPTION	PACKAGING	MINIMUM ORDER QUANTITY (MOQ)
DF300H910N95	H910 Plus N95 Disposable Mask, Head Strap	50 pieces per box, 12 boxes per case, 600 pieces per case	1 Case

INDUSTRIES & APPLICATIONS

For non-oil particles respiratory protection in industries such as construction, mining, textile, manufacturing, wood processing, pharmacy, electronics and automotive manufacturing.

CERTIFICATION

NIOSH approved N95 particulate respirator.

STORAGE


Store the product in its original packaging in a cool, dry place away from direct sunlight or high humidity area. Best to be used within three years after produced.

Honeywell

HOW TO FIT A MASK CORRECTLY?

For proper respiratory protection, you must ensure that there is no air leakage. Therefore, your face should be clean-shaven. Move the mask smoothly, from right to left, up and down, to achieve the best position. The facial fit should be checked as follows:

- Place both hands over the mask and inhale sharply.
- If you feel the air entering around the edges, tighten the nosepiece.

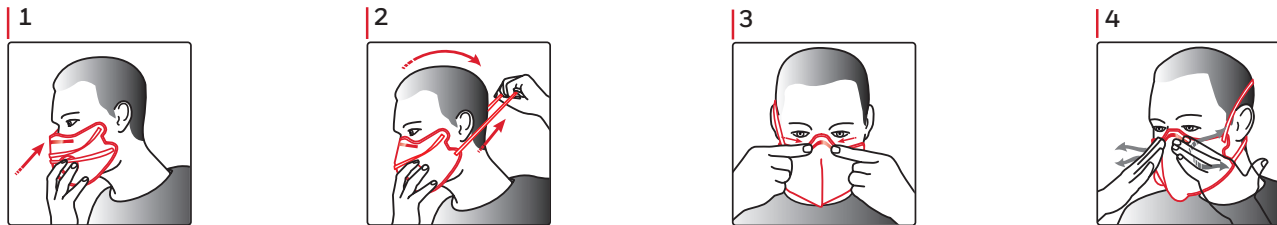

- 1 • Cup the mask in the hand.
- 2 • Put the mask on your face starting at your chin.
 - First, place the lower head strap around the neck below the ears, then place the upper head strap above the ears.
- 3 • Move smoothly, right and left, up and down, in order to achieve the optimal position of the mask on the face.
- 4 Check for leaks (pre-use check) as follows:
 - Place both hands over the mask (do not disturb the position of the respirator) and inhale sharply.
 - If you feel air leaks, readjust the head straps and/or the nose-piece.

INSTRUCTIONS FOR USE

1. Discard the respirator and replace with a new one if:
 - Excessive clogging of the respirator causes breathing difficulty.
 - The respirator becomes damaged.
2. Visually inspect the filtering facepiece prior to each use to assure that there are no holes in the breathing zone, especially around the welded attachment of the headbands to ensure no damage has occurred. Discard respirator if any visual signs of holes or damage.
3. Leave the contaminated area if dizziness, irritation, or other distress occurs.
4. Do NOT use for gases, vapors, oil-based mists, asbestos, paint spray, or sandblasting.
5. Do NOT use for particulate concentrations exceeding ten times PEL

Disclaimer:

This respirator helps protect against specific contaminants. It may not eliminate the risk of contracting diseases or infections. **Misuse may result in sickness or death.** Materials that may come into contact with the wearer's skin could cause allergic reactions to susceptible individuals. For more information or assistance on Honeywell respiratory products, contact your local Honeywell distributor.

For more information

www.honeywellsafety.com

Asia Pacific Headquarters

Honeywell Safety & Productivity Products
Industrial Safety
Level 25, UOA Corporate Tower,
Lobby B, The Vertical, Bangsar
South City, 59200
Kuala Lumpur, Malaysia
Phone: +603-2777 3948/ 3950
Email: hsp.asean@Honeywell.com

Singapore: +65 6714 6800
Indonesia: +62 21 2964 0328
Philippines: +632 730 7300
Thailand: +66 2 693 3099
Vietnam: +84 28 5411 2260

H910_DTS_A4 | Rev 01 | 08/20
© 2020 Honeywell International Inc.

THE
FUTURE
IS
WHAT
WE
MAKE IT

Honeywell