


Handgewindebohrer

Hand Taps

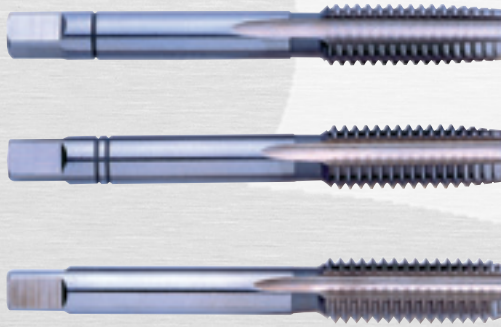

EVENTUS

Art. 1005

DIN 352, HSSG, profilgeschliffen und hinterschlifflin, für metrisches ISO-Gewinde DIN 13, Toleranz 6H = ISO2.

DIN 352, HSSG, profile-ground and backed off, for metric ISO-thread DIN 13, tolerance 6H = ISO2.

Satz zu 3 Stück:
Vor-, Mittel- und Fertigschneider.

Set of 3:
Taper, Second and Plug.

CODE		M								EAN-CODE
				mm	mm	mm	mm	mm	g	4026558.....
10001	No. I	M 3,0	0,50	40	11	3,5	2,7	2,5	2	100012
10002	No. II									100029
10003	No. III									100036
10004	Set								6	100043
10005	No. I	M 4,0	0,70	45	13	4,5	3,4	3,3	4	100050
10006	No. II									100067
10007	No. III									100074
10008	Set								12	100081
10009	No. I	M 5,0	0,80	50	16	6	4,9	4,2	8	100098
10010	No. II									100104
10011	No. III									100111
10012	Set								24	100128
10013	No. I	M 6,0	1,00	50	19	6	4,9	5	9	100135
10014	No. II									100142
10015	No. III									100159
10016	Set								27	100166
10017	No. I	M 8,0	1,25	56	22	6	4,9	6,75	11	100173
10018	No. II									100180
10019	No. III									100197
10020	Set								33	100203
10021	No. I	M 10,0	1,50	70	24	7	5,5	8,5	20	100210
10022	No. II									100227
10023	No. III									100234
10024	Set								60	100241
10025	No. I	M 12,0	1,75	75	29	9	7	10,25	34	100258
10026	No. II									100265
10027	No. III									100272
10028	Set								102	100289
10029	No. I	M 14,0	2,00	80	30	11	9	12	52	100296
10030	No. II									100302
10031	No. III									100319
10032	Set								156	100326
10033	No. I	M 16,0	2,00	80	32	12	9	14	60	100333
10034	No. II									100340
10035	No. III									100357
10036	Set								180	100364
10037	No. I	M 18,0	2,50	95	40	14	11	15,5	100	100371
10038	No. II									100388
10039	No. III									100395
10040	Set								300	100401
10041	No. I	M 20,0	2,50	95	40	16	12	17,5	130	100418
10042	No. II									100425
10043	No. III									100432
10044	Set								390	100449
10045	No. I	M 22,0	2,50	100	40	18	14,5	19,5	175	100456
10046	No. II									100463
10047	No. III									100470
10048	Set								525	100487
10049	No. I	M 24,0	3,00	110	50	18	14,5	21	205	100494
10050	No. II									100500
10051	No. III									100517
10052	Set								615	100524
10053	No. I	M 27,0	3,00	110	50	20	16	24	260	100531
10054	No. II									100548
10055	No. III									100555
10056	Set								780	100562
10057	No. I	M 30,0	3,50	125	56	22	18	26,5	380	100579
10058	No. II									100586
10059	No. III									100593
10060	Set								1140	100609