



Pocket SSD USB 3.2 Gen 2

PN: 32415, 32416, 32417, 3241832282, 32283, 32284, 32285, 32190, 32191, 32192, 32193, 32194, 32195, 32196, 32197, 32432, 32433, 32434, 32435

Description

Lightning-Fast Performance: Engineered for both PC and Mac, this SSD features a USB 3.2 Gen 2 interface, delivering blazing data transfer speeds of up to 1000MB/s. Whether you're editing high-res videos, managing massive data files, or maximizing gaming performance, this SSD ensures your workflow stays smooth and fast. It comes with a USB-C to USB-C cable for seamless connectivity across various devices.

Rock-Solid and Secure: Built with flash memory, the Pocket SSD offers exceptional speed and reliability. With no moving parts, it's completely silent, more durable, and uses less power—perfect for tech enthusiasts on the go.

Compact Powerhouse: Designed for ultimate portability, the Pocket SSD is ultra-lightweight at just 58 grams and measures under 96 mm in length, small enough to slip into your back pocket. Its rugged design resists daily wear and tear, while the specially textured surface provides a secure grip, preventing accidental slips.

Smart Backup with Nero: For added peace of mind, Nero Backup software is included to help you back up your files, folders, and drives effortlessly. Schedule automatic backups at your convenience, ensuring your data is always safe.

Note: Nero Backup is compatible only with Windows OS.

Convenient Keyring and Cable Holder: The included keyring lets you attach the SSD securely to your belt loop or backpack. Plus, the thoughtfully designed cable holder keeps your cable neatly stored and tangle-free, making it perfect for travel.

*Actual transfer speeds depend on file size, computer performance and operating system.



PN: 32415, 32416, 32417, 32418, 32282, 32283, 32284, 32285, 32190, 32191, 32192, 32193, 32194, 32195, 32196, 32197, 32432, 32433, 32434, 32435

System Requirements

- USB 3.2 Gen 2 host port (also compatible with USB 2.0**)
- Windows 11, 10, 8, Mac OS X 10.2 or higher

**For optimal performance, the drive must be connected to a USB 3.2 Gen 2 host controller

Product Specifications

Power: Bus powered via USB cable

Interface: USB 3.2 Gen 2

Data Transfer Rate: 10 Gbps

SSD Form Factor: M.2


Read Speed: up to 1000MB/s

Write Speed: up to 1000MB/s

Enclosure Material: Fireproof PC

Product Weight: 58 grams (approx)

Dimensions: 96.13mm x 45.12mm x 10mm (L x W x H)

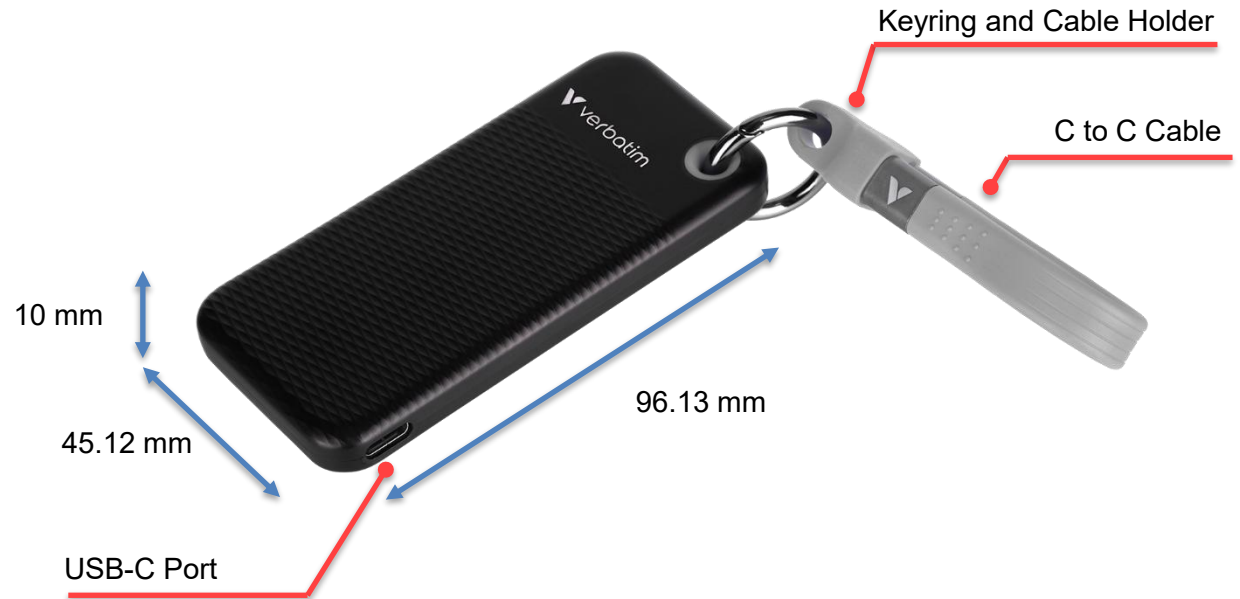

Storage and Operating Conditions

Operating Temperature: -10°C ~ +59°C

Operating Humidity: 20% ~65% RH

Storage Temperature: -10°C ~ +45°C

Languages

Front of pack: English

Back of pack: English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Quick Installation Languages

English, German + Technical support text in English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Reorder No.	Description	Tariff Code	Barcode	EAN-128	EAN-14
32432	Pocket SSD USB 3.2 Gen 2 128GB Black/Grey	84717098	023942324324	(02)00023942324324(37)10(91)468	50023942324329
32433	Pocket SSD USB 3.2 Gen 2 128GB Black/Blue	84717098	023942324331	(02)00023942324331(37)10(91)468	50023942324336
32434	Pocket SSD USB 3.2 Gen 2 128GB Black/Red	84717098	023942324348	(02)00023942324348(37)10(91)468	50023942324343
32435	Pocket SSD USB 3.2 Gen 2 128GB Black/Orange	84717098	023942324355	(02)00023942324355(37)10(91)468	50023942324350
32415	Verbatim Pocket SSD USB 3.2 Gen 2 256GB Black/Grey	84717098	023942324157	(02)00023942324157(37)10(91)468	50023942324152
32416	Verbatim Pocket SSD USB 3.2 Gen 2 256GB Black/Blue	84717098	023942324164	(02)00023942324164(37)10(91)468	50023942324169
32417	Verbatim Pocket SSD USB 3.2 Gen 2 256GB Black/Red	84717098	023942324171	(02)00023942324171(37)10(91)468	50023942324176
32418	Verbatim Pocket SSD USB 3.2 Gen 2 256GB Black/Orange	84717098	023942324188	(02)00023942324188(37)10(91)468	50023942324183
32282	Verbatim Pocket SSD USB 3.2 Gen 2 512GB Black/Grey	84717098	023942322825	(02)00023942322825(37)10(91)468	50023942322820
32283	Verbatim Pocket SSD USB 3.2 Gen 2 512GB Black/Blue	84717098	023942322832	(02)00023942322832(37)10(91)468	50023942322837
32284	Verbatim Pocket SSD USB 3.2 Gen 2 512GB Black/Red	84717098	023942322849	(02)00023942322849(37)10(91)468	50023942322844
32285	Verbatim Pocket SSD USB 3.2 Gen 2 512GB Black/Orange	84717098	023942322856	(02)00023942322856(37)10(91)468	50023942322851
32190	Verbatim Pocket SSD USB 3.2 Gen 2 1TB Black/Grey	84717098	023942321903	(02)00023942321903(37)10(91)468	50023942321908
32191	Verbatim Pocket SSD USB 3.2 Gen 2 1TB Black/Blue	84717098	023942321910	(02)00023942321910(37)10(91)468	50023942321915
32192	Verbatim Pocket SSD USB 3.2 Gen 2 1TB Black/Red	84717098	023942321927	(02)00023942321927(37)10(91)468	50023942321922
32193	Verbatim Pocket SSD USB 3.2 Gen 2 1TB Black/Orange	84717098	023942321934	(02)00023942321934(37)10(91)468	50023942321939
32194	Verbatim Pocket SSD USB 3.2 Gen 2 2TB Black/Grey	84717098	023942321941	(02)00023942321941(37)10(91)468	50023942321946
32195	Verbatim Pocket SSD USB 3.2 Gen 2 2TB Black/Blue	84717098	023942321958	(02)00023942321958(37)10(91)468	50023942321953
32196	Verbatim Pocket SSD USB 3.2 Gen 2 2TB Black/Red	84717098	023942321965	(02)00023942321965(37)10(91)468	50023942321960
32197	Verbatim Pocket SSD USB 3.2 Gen 2 2TB Black/Orange	84717098	023942321972	(02)00023942321972(37)10(91)468	50023942321977

Reorder No.	
Product Dimensions L x W x H	96.13mm x 45.12mm x 10mm
Product Weight	58g
Units per Pack	1
Pack Dimensions L x W x H	120mm x 82mm x 32mm
Pack Weight	90.5
Units per Outer Carton (MOQ)	10
Outer Carton Dimensions L x W x H	280mm x 180mm x 100mm
Outer Cartons Weight	1100
Outer Cartons per Layer	20
Layers per Pallet	12
Units per Pallet	2400



Pack Content

- Pocket SSD USB 3.2 Gen 2
- Cloth bag
- Nero Backup Software
- USB-C to USB-C cable
- QSG