


PHE 1120TGRSB

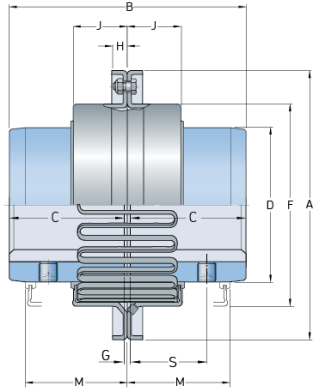

Size	1120
Nominal torque (lbft)	10104.6
Nominal torque (Nm)	13700
Min. bore (mm)	60
Max speed (r/min)	2700
Min. bore (in)	2.36
Max. bore (mm)	136
Max. bore (in)	5.35
Weight (kg)	32.4
Weight (lbs)	71.43