

ABL



LOW VOLTAGE DEVICES

JULY 2017



THE ORIGINAL. SINCE 1925.

LOW VOLTAGE DEVICES

The ABL Plug **4**

SCHUKO **6**

French/Belgian standard **26**

Swiss standard **36**

International standard **42**

Outlet Boxes, Perilex
Industrial Ethernet **46**

Item Number Directory **51**



THE ABL PLUG

In 1925, Albert Büttner, the founder of our company, invented the SCHUKO plug – the most widespread AC power plug and socket system in the world: Plugs, connectors and sockets for trade, construction and industry.

Apart from SCHUKO, we also offer plugs and sockets according to many other international standards. We develop and manufacture products of the highest 'Made in Germany' quality.

We keep developing our ABL plug further so that it remains ahead of the competition. New materials, new technical features and optimized power connection technologies are the topics that drive us forward.

1 ELAMID

We guarantee superior resilience and impact resistance for our products manufactured from Elamid high performance plastic. Elamid has a high chemical and UV resistance as well as an extremely wide temperature tolerance (-40°C to 80°C). Elamid products, such as those from our Hightech range, are perfect for trade and industrial applications.



2 ELAMID 2K

With the Elamid 2K technology, we succeeded in creating a perfect combination of rubber and Elamid. The result is a range of high quality products for heavy duty applications on construction and industrial sites.

Plugs and connectors from our professionell range are extremely rugged and offer a firm and non-slip grip. With the built-in SCHUKOplus socket, our customers have the choice of another top product made from Elamid 2K.

All Elamid 2K products comply with the IP44 degree of protection, including when they are plugged in.



3 QUICK RELEASE LOCK

To allow users to combine grip and contact carrier easily and quickly, we have created the ABL quick release lock. A mere quarter turn is all that's required to ensure a secure connection between handle and contact carrier.



4 VOLTAGE INDICATOR

Just want to check for voltage? No problem with the voltage indicator available for ABL connectors and triple suspended connectors, making annoying double-checking trips on construction sites a thing of the past.



5 SLIDING CONTACTS

Our solid metal sliding contacts guarantee a long working life and a secure protective earth connection.





PLUGS AND CONNECTORS

| | |
|---------------------|----|
| SCHUKO Professional | 8 |
| SCHUKO Hightech | 10 |
| SCHUKO Classic | 12 |
| SCHUKO Basic | 16 |

SOCKET OUTLETS

| | |
|---------------------|----|
| SCHUKO Professional | 17 |
| SCHUKO Classic | 18 |
| SCHUKO Basic | 23 |
| ACCESSORIES | 25 |
| ADAPTER | 25 |



ELAMID 2K PLUG

with quick release fastener and twin earthing system · SCHUKO and French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1529100 | 91 | 5 |



ELAMID 2K CONNECTOR

with voltage indicator ⊗, quick release fastener and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1589200 | 166 | 5 |



ELAMID 2K PLUG

with quick release fastener and twin earthing system · SCHUKO and French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|-----------|----------|---------------|----|
| red/black | 1529140 | 91 | 5 |



ELAMID 2K CONNECTOR

with voltage indicator ⊗, quick release fastener and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|-----------|----------|---------------|----|
| red/black | 1589240 | 166 | 5 |



ELAMID 2K PLUG

with quick release fastener and twin earthing system · SCHUKO and French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|------------|----------|---------------|----|
| grey/black | 1529160 | 91 | 5 |



ELAMID 2K CONNECTOR

with voltage indicator ⊗, quick release fastener and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|------------|----------|---------------|----|
| grey/black | 1589260 | 166 | 5 |

SCHUKO PROFESSIONAL

THREE-WAY CONNECTORS

2-pole + \oplus , 16 A 250 V, DIN/VDE 0620 and IEC 60884 compliant · for wires up to bis 3 x 2,5 mm² splash-proof IP54 · \diamond



THREE-WAY SOLID RUBBER CONNECTOR

with voltage indicator \otimes and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1173503 | 426 | 5 |



THREE-WAY SOLID RUBBER CONNECTOR

with voltage indicator \otimes and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|-----------|----------|---------------|----|
| red/black | 1173543 | 426 | 5 |



THREE-WAY SOLID RUBBER CONNECTOR

with voltage indicator \otimes and self-closing lid

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|------------|----------|---------------|----|
| grey/black | 1173563 | 426 | 5 |

SCHUKO PROFESSIONAL

PRESSURISED WATER-IMPERMEABLE

2-pole + \oplus , 16 A 250 V, DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 2,5 mm² pressurised water-impermeable IP68 · \diamond



THERMOPLASTIC PLUG

with protective cap

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| blue | 1979850 | 150 | 5 |



THERMOPLASTIC CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| blue | 1976850 | 150 | 5 |



THERMOPLASTIC PLUG

with protective cap

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| blue | 1989850 | 130 | 5 |

SCHUKO HIGHTECH PLUGS

2-pole + , 16 A 250 V, DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 2,5 mm² splash-proof IP44 ·  ELAMID



ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | 1519150 | 78 | 10 |



ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | 1519140 | 78 | 10 |



ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1519100 | 78 | 10 |



ELAMID CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| blue | 1579150 | 75 | 10 |

with shutter


| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| blue | 1579050 | 75 | 10 |



ELAMID CONNECTOR

with collar / cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| blue | 1579350 | 98 | 10 |

with collar / cover
with shutter
splashproof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| blue | 1579250 | 98 | 10 |



ELAMID CONNECTOR


| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| red | 1579140 | 75 | 10 |

with shutter


| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| red | 1579040 | 75 | 10 |



ELAMID CONNECTOR

with collar / cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| red | 1579340 | 98 | 10 |

with collar / cover
with shutter
splashproof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| red | 1579240 | 98 | 10 |



ELAMID CONNECTOR


| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| black | 1579100 | 75 | 10 |

with shutter


| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| black | 1579000 | 75 | 10 |



ELAMID CONNECTOR

with collar / cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| black | 1579300 | 98 | 10 |

with collar / cover
with shutter
splashproof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|-----------------|----|
| black | 1579200 | 98 | 10 |

SCHUKO CLASSIC

PLUGS AND CONNECTORS

2-pole + ⊕, 16 A 250 V, DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 2,5 mm²



SOLID RUBBER PLUG

with metal quick release
with twin earthing system
SCHUKO and
French/Belgian standard
splash-proof IP44 · ⚡

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1129190 | 106 | 20 |



SOLID RUBBER CONNECTOR

with quick release fastener

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1189090 | 137 | 10 |



SOLID RUBBER CONNECTOR

with quick release fastener
with collar/cover
splash-proof IP44 · ⚡

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1189290 | 175 | 10 |

SCHUKO CLASSIC

THREE-WAY CONNECTOR

2-pole + ⊕, 16 A 250 V, according to DIN/VDE 0620,
for wires up to bis 3 x 2,5 mm²



THREE-WAY SOLID RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1473190 | 368 | 5 |

SCHUKO CLASSIC

PLUGS AND CONNECTORS

2-pole + \oplus , 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 2,5 mm²



SOLID RUBBER PLUG

with twin earthing system
SCHUKO and
French/Belgian standard
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1149290 | 99 | 20 |



SOLID RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1169090 | 119 | 10 |



SOLID RUBBER CONNECTOR

with collar / cover
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1169290 | 175 | 10 |

SCHUKO CLASSIC

PLUGS AND CONNECTORS

2-pole + \oplus , 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 2,5 mm²



RUBBER PLUG

with twin earthing system
SCHUKO and
French/Belgian standard
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1149190 | 86 | 20 |



RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1199090 | 104 | 10 |



RUBBER CONNECTOR

with collar/cover
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| black | 1199290 | 137 | 10 |

SCHUKO CLASSIC

PLUGS AND CONNECTORS

2-pole + ⊕, 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 1,5 mm²



SOLID RUBBER PLUG

splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1429190 | 72 | 20 |



SOLID RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1489090 | 125 | 10 |

SCHUKO CLASSIC

PLUGS AND CONNECTORS

2-pole + ⊕, 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884 · for wires up to bis 3 x 1,5 mm²



RUBBER PLUG

with twin earthing system
SCHUKO and
French/Belgian standard
splash-proof IP44 · ⚡

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1419190 | 64 | 20 |
| orange | 1419170 | 64 | 20 |
| red | 1419140 | 64 | 20 |



RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1479090 | 117 | 10 |
| orange | 1479070 | 117 | 10 |
| red | 1479040 | 117 | 10 |



PVC PLUG MINI

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------------|--------------------|----|
| grey | 1418060 | 40 | 20 |
| white | 1418080 | 40 | 20 |
| yellow | 1418050 | 40 | 20 |
| black | 1418000 | 40 | 20 |



PVC CONNECTOR MINI

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------------|--------------------|----|
| grey | 1679060 | 83 | 10 |
| white | 1679080 | 83 | 10 |
| yellow | 1679050 | 83 | 10 |
| black | 1679000 | 83 | 10 |



PVC PLUG MAXI

with twin earthing system
SCHUKO and
French/Belgian standard
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------------|--------------------|----|
| grey | 1428160 | 56 | 20 |
| white | 1428180 | 56 | 20 |
| yellow | 1428150 | 56 | 20 |



PVC CONNECTOR MAXI

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------------|--------------------|----|
| grey | 1478060 | 92 | 10 |
| white | 1478080 | 92 | 10 |
| yellow | 1478050 | 92 | 10 |



THERMOPLASTIC PLUG

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1116100 | 27 | 50 |
| white | 1116110 | 27 | 50 |



THERMOPLASTIC ANGLE PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1400390 | 35 | 20 |
| white | 1400380 | 35 | 20 |



THERMOPLASTIC ANGLE PLUG

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1107100 | 34 | 50 |
| white | 1107110 | 34 | 50 |





THERMOPLASTIC CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1176100 | 31 | 20 |
| white | 1176110 | 31 | 20 |

SCHUKO PROFESSIONAL

SCHUKOplus PLUGS

2-pole + \ominus , 16 A 250 V, DIN/VDE 0620
 splash-proof IP54 ·  · 
 with Screw terminals



ELAMID 2 K SOCKET PLUG

flush mounting

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------------|------------------|-----|
| blue | 1561050 | 53 | 100 |
| black | 1561000 | 53 | 100 |
| red | 1561040 | 53 | 100 |
| yellow | 1561030 | 53 | 100 |
| grey | 1561060 | 53 | 100 |




ELAMID 2 K SOCKET PLUG

flush mounting
with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------------|------------------|-----|
| blue | 1562050 | 55 | 100 |

 
SCHUKO PROFESSIONAL

2-pole + \ominus , 16 A 250 V, acc. to DIN/VDE 0620 and
 IEC 60884 · Pressurised water-impermeable IP68 · 



THERMOPLASTIC WALL-MOUNTED SOCKET OUTLET

with 2 x M20 screw connection

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|---|----------------|------------------|----|
| blue  | 1977751 | 180 | 5 |



THERMOPLASTIC PANEL-MOUNTED SOCKET

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------------|------------------|----|
| blue | 1987951 | 90 | 5 |

SCHUKO CLASSIC

SOCKET OUTLETS

2-pole + ⊕, 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884 · with screw terminals



THERMOPLASTIC SOCKET OUTLET

flush mounting IP54

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|-----|
| black | 1461000 | 38 | 100 |
| red | 1461040 | 38 | 100 |
| blue | 1461050 | 38 | 100 |
| grey | 1461060 | 38 | 100 |



THERMOPLASTIC SOCKET OUTLET

flush mounting IP54

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|-----|
| black | 1461100 | 38 | 100 |
| red | 1461140 | 38 | 100 |
| blue | 1461150 | 38 | 100 |
| grey | 1461160 | 38 | 100 |



THERMOPLASTIC SOCKET OUTLET

flush mounting

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|-----|
| black | 1461300 | 29 | 100 |
| blue | 1461350 | 29 | 100 |
| grey | 1461360 | 29 | 100 |



THERMOPLASTIC SOCKET OUTLET

flush mounting IP54 with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|-----|
| blue | 1662050 | 53 | 100 |

SCHUKO CLASSIC

BOWAmini SOCKET OUTLETS

94 x 94 mm



COVER

with hinged lid
stained steel, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|------------------|----|
| 1471ESM | 315 | 1 |



COVER

with hinged lid
platinum, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|------------------|----|
| 1471PLM | 315 | 1 |



COVER

with hinged lid
brass, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|------------------|----|
| 1471MSM | 315 | 1 |




THERMOPLASTIC SOCKET OUTLET

with SCHUKO socket outlet

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|------------------|----|
| 1471601 | 125 | 1 |

All standard socket outlets with an 80 mm cover and support ring fastening available for installation engineering, communication and telecommunications can be mounted into the 1632500 enclosure.

Simple and safe connection with coupling brackets.

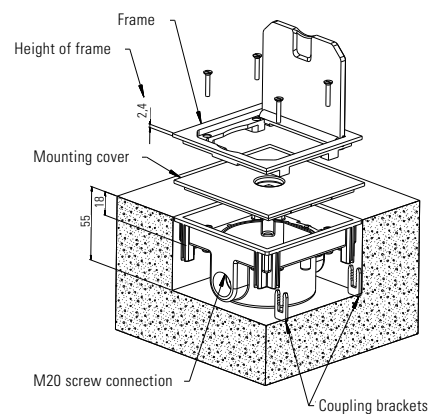



COVER

with hinged lid
stainless steel, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| 1632ESM | 498 | 1 |



COVER

with hinged lid
platinum, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| 1632PLM | 498 | 1 |



COVER

with hinged lid
brass, matt
drip-proof IP41

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| 1632MSM | 498 | 1 |



THERMOPLASTIC DOUBLE SOCKET OUTLET

with double SCHUKO outlet

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| 1632602 | 281 | 1 |




THERMOPLASTIC HOUSING BASE

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| 1632500 | 187 | 1 |

All standard socket outlets with an 80 mm cover and support ring fastening available for installation engineering, communication and telecommunications can be mounted into the 1632500 enclosure.

Simple and safe connection with coupling brackets.

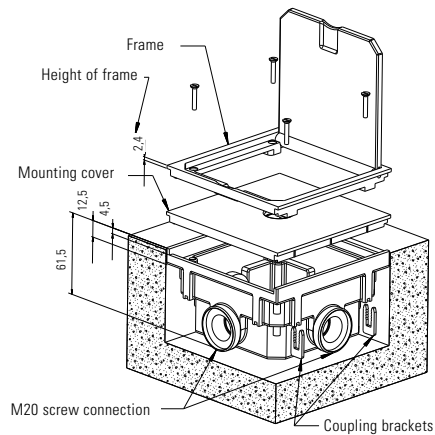





SOCKET OUTLET

cover with hinged lid made of aluminium die-cast
base made of thermoplastic
drip-proof IP41
with shutter (1471461)

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| grey | 1471460 | 301 | 1 |
| grey | 1471461 | 301 | 1 |



DOUBLE SOCKET OUTLET

cover with hinged lid made of aluminium die-cast
base made of aluminium die-cast
drip-proof IP41

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| grey | 1632490 | 575 | 1 |



HOUSING

cover with hinged lid
made of aluminium die-cast
base made of thermoplastic
drip-proof IP41

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| grey | 1632497 | 375 | 1 |



SOCKET OUTLET

cover with cinged lid
made of aluminium die-cast
base made of thermoplastic
watertight IP66

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| grey | 1471360 | 740 | 1 |



THERMOPLASTIC SOCKET OUTLET

flush mounting · suitable for
installation in BOWAmini

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| white | 1111810 | 32 | 100 |




THERMOPLASTIC SOCKET OUTLET

flush mounting · with shutter
suitable for installation in BOWAmini

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| white | 1111710 | 33 | 100 |

SCHUKO BASIC

SOCKET OUTLETS

2-pole + , 16 A 250 V,
acc. to DIN/VDE 0620 and IEC 60884



SURFACE-MOUNTED SOCKET OUTLET

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1491010 | 79 | 10 |



BASE PLATE

for item No. 1491010

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1491008 | 8 | 10 |



SURFACE-MOUNTED SOCKET OUTLET

Double

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1492010 | 128 | 10 |



BASE PLATE

for item No. 1492010

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1492008 | 13 | 10 |



SURFACE-MOUNTED SOCKET OUTLET

Triple

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1493010 | 197 | 5 |



BASE PLATE

for item No. 1493010

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1493008 | 18 | 10 |



SURFACE-MOUNTED SOCKET OUTLET

Quadruple

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1694010 | 214 | 5 |



BASE PLATE

for item No.1694010

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 0004060 | 32 | 10 |

ACCESSORIES

SOCKET OUTLETS



SURFACE-MOUNTED HOUSING

for socket outlet
1461, 1561, 1562, 1662

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| black | 1461007 | 49 | 10 |



MOUNTING PLATE

for surface-mounted housing
for snapping onto DIN rail
acc. to DIN EN 60715 35 mm

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|-----|
| 1461SB | 14 | 100 |



RUBBER SEAL

for socket outlet 1461, 1462,
CZ, SEV, UL and BS

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|-----|
| black | 8632316 | 3 | 100 |

ADAPTER



CEE PLUG ON SCHUKO SOCKET

3-pole, 16A, 230V, 6 h blue
splash-proof IP44

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| ADP050 | 165 | 5 |



CEE PLUG ON SOCKET F/B-STANDARD

3-pole, 16A, 230V, 6 h blue
splash-proof IP44

| ITEM NO. | WEIGHT g/EACH | PU |
|----------|---------------|----|
| ADP052 | 165 | 5 |



FRENCH/BELGIAN STANDARD


PLUGS AND CONNECTORS

| | |
|----------|----|
| HIGHTECH | 28 |
| CLASSIC | 30 |

SOCKET OUTLETS

| | |
|----------|----|
| HIGHTECH | 32 |
| CLASSIC | 33 |
| BASIC | 34 |

HIGHTECH PLUGS

2-pole + ⊕, 16 A 250 V, acc. to DIN/VDE 0620 and IEC 60884
for wires up to bis 3 x 2,5 mm² · splash-proof IP44 ·  ELAMID



ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | 1519150 | 78 | 10 |



ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | 1519140 | 78 | 10 |



 
ELAMID PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1519100 | 78 | 10 |



HIGHTECH CONNECTORS

2-pole + , 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard · for wires up to bis 3 x 2,5 mm²

 ELAMID



 
ELAMID CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | 1579052 | 75 | 10 |



ELAMID CONNECTOR

with shutter
with collar and cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | 1579252 | 98 | 10 |



ELAMID CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | 1579042 | 75 | 10 |



ELAMID CONNECTOR

with shutter
with collar and cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | 1579242 | 98 | 10 |



ELAMID CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1579002 | 75 | 10 |



ELAMID CONNECTOR

with shutter
with collar and cover
splash-proof IP44 · 

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1579202 | 98 | 10 |

CLASSIC

PLUGS AND CONNECTORS

2-pole + ⊕, 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard · for wires up to bis 3 x 2,5 mm² splash-proof IP44



RUBBER PLUG

with twin earthing system
SCHUKO and
French/Belgian standards

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1149190 | 86 | 20 |



RUBBER CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1199592 | 170 | 10 |

CLASSIC

THREE-WAY CONNECTORS

2-pole + ⊕, 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard · for wires up to bis 3 x 2,5 mm²



THREE-WAY SOLID RUBBER CONNECTOR SELF-CLOSING LID

with shutter
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1473597 | 486 | 5 |



THREE-WAY SOLID RUBBER CONNECTOR

splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1473292 | 486 | 5 |



THREE-WAY SOLID RUBBER CONNECTOR

with shutter
with voltage indicator ⊗

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1473692 | 383 | 5 |

CLASSIC

PLUGS AND CONNECTORS

2-pole + Ⓢ, 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard · for wires up to 3 x 1,5 mm²



RUBBER PLUG

with twin earthing system
SCHUKO and
French/Belgian standards
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1419190 | 64 | 20 |



RUBBER CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1479091 | 117 | 10 |



RUBBER CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1479092 | 117 | 10 |



RUBBER CONNECTOR

splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1479291 | 166 | 10 |



RUBBER CONNECTOR

with shutter
splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| black | 1479292 | 166 | 10 |

CLASSIC

PLUGS AND CONNECTORS

2-pole + Ⓢ, 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard · for wires up to bis 3 x 1,5 mm²



PVC PLUG

with twin earthing system
SCHUKO and
French/Belgian standard

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| grey | 1418060 | 40 | 20 |
| white | 1418080 | 40 | 20 |
| black | 1418000 | 40 | 20 |



PVC CONNECTOR

with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| grey | 1679062 | 83 | 10 |
| white | 1679082 | 83 | 10 |
| black | 1679002 | 83 | 10 |

HIGHTECH

SOCKET OUTLETS

2-pole + \ominus , 16 A 250 V, acc. to NF C61-314 French standard and NBN C61-112 Belgian standard, IP54



THERMOPLASTIC SOCKET OUTLET

flush mounting IP54 \diamond
with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| black | 1662002 | 53 | 100 |
| blue | 1662052 | 53 | 100 |
| grey | 1662062 | 53 | 100 |



CLASSIC

BOWAmini SOCKET OUTLETS

94 x 94 mm



COVER

with hinged lid
stainless steel matt
drip-proof IP41

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|--------------------|----|
| 1471ESM | 315 | 1 |



COVER

with hinged lid
platinum, matt
drip-proof IP41

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|--------------------|----|
| 1471PLM | 315 | 1 |



COVER

with hinged lid
brass, matt
drip-proof IP41

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|--------------------|----|
| 1471MSM | 315 | 1 |



SOCKET OUTLET

thermoplastic
with French/Belgian standard
and shutter

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|--------------------|----|
| 1471602 | 125 | 1 |

CLASSIC

BOWAcompact SOCKET OUTLETS

2-pole + ⊕, 16 A 250 V, acc. to NF C61-314 French standard and
NBN C61-112 Belgian standard · for wires up to bis 3 x 1,5 mm²



SOCKET OUTLET MINI

drip-proof IP41
cover with hinged lid
made of aluminium die-cast
base made of thermoplastic
with shutter

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| grey | 1471462 | 301 | 1 |

BASIC SOCKET OUTLETS

2-pole + , 16 A 250 V, NF C61-314 French standard and
NBN C61-112 Belgian standard




THERMOPLASTIC SOCKET OUTLET

flush mounting
suitable for installation in
BOWA.94 · with shutter

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| white | 1111712 | 33 | 100 |

BASIC SOCKET OUTLETS

2-pole + , 16 A 250 V



SURFACE-MOUNTED SOCKET OUTLET

quadruple, without earthing system

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| white | 1804010 | 159 | 5 |

Accessories on page 25





SWISS STANDARD

PLUGS AND CONNECTORS 38

SOCKET OUTLETS 40

PLUGS & CONNECTORS

acc. to SEV Typ 23, 25
splash-proof IP44



RUBBER PLUG 16 A 250 V

acc. to SEV 5934 Typ 23

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|-----------|----------|------------------|----|
| dark blue | SEV23S | 80 | 20 |



RUBBER CONNECTOR 16 A 250 V

acc. to SEV 5934 Typ 23
with collar and cover

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|-----------|----------|------------------|----|
| dark blue | SEV23K2 | 132 | 10 |



RUBBER PLUG 16 A 400 V

acc. to SEV 5932 Typ 25

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | SEV25S | 98 | 20 |



RUBBER CONNECTOR 16 A 400 V

acc. to SEV 5932 Typ 25
with collar and cover

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| red | SEV25K2 | 138 | 10 |

PLUGS & CONNECTORS

acc. to SEV Typ 12, 13, 15
splash-proof IP44



RUBBER PLUG 10 A 250 V

acc. to SEV 6534 Typ 12

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|------------|----------|------------------|----|
| light blue | SEV12S2 | 79 | 20 |



RUBBER CONNECTOR 10 A 250 V

acc. to SEV 6535 Typ 13
with collar and cover

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|------------|----------|------------------|----|
| light blue | SEV13K2 | 132 | 10 |



RUBBER PLUG 10 A 400 V

acc. to SEV 6532 Typ 15

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| orange | SEV15S | 95 | 20 |



RUBBER CONNECTOR 10 A 400 V

SEV 6532 Typ 15
with collar and cover

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| orange | SEV15K2 | 135 | 10 |

THREE-WAY CONNECTOR

acc. to SEV Typ 13



THREE-WAY SOLID RUBBER CONNECTOR 10 A 250 V

acc. to SEV 6535 Type 13 with voltage
indicator and self-closing lid
splash-proof IP54

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | SEV313K | 486 | 5 |

SOCKET OUTLETS

16 A

acc. to SEV Typ 23, 25, IP54 · 



THERMOPLASTIC SOCKET OUTLET 16 A 250 V

flush mounting
acc. to SEV 5934 type 23
with seal in hinged lid

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|---------------|----------|--------------------|-----|
| grey/ blue | 1461965 | 40 | 100 |




THERMOPLASTIC SOCKET OUTLET 16 A 400 V


flush mounting
acc. to SEV 5932 type 25
with seal in hinged lid

| COLOUR | ITEM NO. | WEIGHT g / EACH | PU |
|--------------|----------|--------------------|----|
| grey/ red | SEV1148 | 65 | 20 |

SOCKET OUTLETS

10 A

acc. to SEV Typ 13, 15, IP54 · 

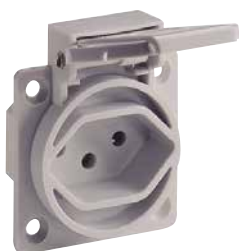

THERMOPLASTIC SOCKET OUTLET 10 A 250 V

flush mounting
acc. to SEV 6535 type 13

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| blue | 1461005 | 37 | 20 |
| black | 1461006 | 37 | 20 |
| grey | 1461066 | 37 | 20 |



THERMOPLASTIC SOCKET OUTLET 10 A 400 V

flush mounting
acc. to SEV 6532 type 15

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|----|
| grey | SEV-100 | 57 | 20 |



INTERNATIONAL STANDARDS

USA/CANADA 44

GB 44

AUSTRALIA, CHINA 45

SOCKET OUTLETS

USA, CANADA

2-pole + \oplus , 15 A 125 V
acc. to UL498/NEMA 5-15 R,
CSA 22.2 Nr. 42



THERMOPLASTIC SOCKET OUTLET

flush mounting
IP54 · \diamond

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| black | UL12500 | 45 | 100 |
| blue | UL12505 | 45 | 100 |
| grey | UL12506 | 45 | 100 |

SOCKET OUTLETS

GB

2-pole + \oplus , 13 A 250 V
acc. to British standard BS1363



THERMOPLASTIC SOCKET OUTLET

flush mounting
IP54

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|------------------|-----|
| black | BS13630 | 38 | 100 |

Accessories on page 25

SOCKET OUTLETS

AUSTRALIA, CHINA

2-pole + \ominus , 250 V,
acc. to Australian standard
AS / NZS 3112



THERMOPLASTIC PANEL-MOUNTED SOCKET OUTLET

colour green
water jet protected IP66

| AMPERE | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| 10 A | 310D062 | 119 | 10 |
| 15 A | 315D062 | 119 | 10 |



THERMOPLASTIC PANEL-MOUNTED SOCKET OUTLET

colour grey
water jet protected IP66

| AMPERE | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| 10 A | 310D066 | 119 | 10 |
| 15 A | 315D066 | 119 | 10 |
| 20 A | 320D066 | 119 | 10 |

SOCKET OUTLETS

AUSTRALIA

acc. to Australian standard
AS / NZS 3123



THERMOPLASTIC PANEL-MOUNTED SOCKET OUTLET

3-pole + \ominus , 500 V
colour grey
water jet protected IP66

| AMPERE | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| 32 A | 432D060 | 183 | 10 |
| 40 A | 440D060 | 183 | 10 |
| 50 A | 450D060 | 183 | 10 |



THERMOPLASTIC PANEL-MOUNTED SOCKET OUTLET

3-pole + N + \ominus , 500 V
colour grey
water jet protected IP66

| AMPERE | ITEM NO. | WEIGHT g / EACH | PU |
|--------|----------|--------------------|----|
| 32 A | 532D060 | 193 | 10 |
| 50 A | 550D060 | 193 | 10 |



OUTLET BOXES 48

PERILEX 49

INDUSTRIAL ETHERNET 50

OUTLET BOXES

with screw terminals
compliant with VDE 0606



THERMOPLASTIC OUTLET BOX

for surface mounting
cover with snap lock
terminals: 5 x 2,5 to* 6 mm²

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2505010 | 80 | 10 |



THERMOPLASTIC OUTLET BOX

for flush mounting and surface mounting · cover with snap lock · terminals: 5 x 2,5 to* 6 mm²

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2505110 | 80 | 10 |



THERMOPLASTIC OUTLET BOX

for flush mounting and surface mounting, claw bracket can be snapped out
cover with snap lock
terminals: 5 x 2,5 to* 6 mm²

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2505210 | 90 | 10 |



BASE PLATE IP44

with two cable entries
for outlet boxes 25055

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2505018 | 32 | 10 |



THERMOPLASTIC OUTLET BOX

for flush mounting
flat version · cover with snap lock
terminals: 5 x 2,5 mm²
extra flat – only 11 mm

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2506110 | 61 | 10 |




THREE-CHAMBER OUTLET BOX

for flush mounting and surface mounting
dowel fastening
terminals: 5 x 2,5 to* 6 mm² / 7 x 2,5 mm²

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2518610 | 166 | 5 |

PERILEX
 PLUG, CONNECTORS
 AND SOCKET OUTLETS

3-pole + N + , 16 A AC 400/230 V
 acc. to DIN 49445/46



DUROPLAST PLUG

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2201110 | 99 | 10 |



DUROPLAST CONNECTOR

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2206110 | 149 | 10 |



DUROPLAST ANGLE PLUG

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2407110 | 113 | 10 |



DUROPLAST FLUSH-MOUNTED SOCKET OUTLET

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2421110 | 142 | 10 |



DUROPLAST FLUSH-MOUNTED SOCKET OUTLET

splash-proof IP44
 with in-wall box

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2451510 | 234 | 10 |



DUROPLAST SURFACE-MOUNTED SOCKET OUTLET

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| white | 2491010 | 136 | 10 |



DUROPLAST SURFACE-MOUNTED SOCKET OUTLET

splash-proof IP44

| COLOUR | ITEM NO. | WEIGHT g/EACH | PU |
|--------|----------|---------------|----|
| grey | 2441860 | 271 | 5 |

INDUSTRIAL ETHERNET



PANEL-MOUNTED SOCKET IP67

access side: IDC insulation-piercing plug technology · outgoing side: 2 x RJ45 Cat.6 modules 8(8)

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|-----------------|----|
| DG-RJ45 | 160 | 10 |



SOCKET PLUG IP55

access side: IDC insulation-piercing plug technology · outgoing side: 1 x RJ45 Cat.6 module 8(8) RJ45K13
2 x RJ45 Cat.6 modules 8(8) RJ45K23

| ITEM NO. | WEIGHT g / EACH | PU |
|----------|-----------------|----|
| RJ45K13 | 70 | 10 |
| RJ45K23 | 100 | 10 |

ITEM NUMBER DIRECTORY

| ITEM NO. | PAGE |
|----------|------|
| 0004060 | 24 |
| 1107100 | 16 |
| 1107110 | 16 |
| 1111710 | 23 |
| 1111712 | 34 |
| 1111810 | 23 |
| 1116100 | 16 |
| 1116110 | 16 |
| 1129190 | 12 |
| 1149190 | 13 |
| 1149190 | 30 |
| 1149290 | 13 |
| 1169090 | 13 |
| 1169290 | 13 |
| 1173503 | 9 |
| 1173543 | 9 |
| 1173563 | 9 |
| 1176100 | 16 |
| 1176110 | 16 |
| 1189090 | 12 |
| 1189290 | 12 |
| 1199090 | 13 |
| 1199290 | 13 |
| 1199592 | 30 |
| 1400380 | 16 |
| 1400390 | 16 |
| 1418000 | 15 |
| 1418000 | 31 |
| 1418050 | 15 |
| 1418060 | 15 |
| 1418060 | 31 |
| 1418080 | 15 |
| 1418080 | 31 |
| 1419140 | 14 |
| 1419170 | 14 |
| 1419190 | 14 |
| 1419190 | 31 |
| 1428160 | 15 |
| 1428180 | 15 |
| 1428150 | 15 |
| 1429190 | 14 |
| 1461000 | 18 |
| 1461005 | 41 |
| 1461006 | 41 |
| 1461007 | 25 |
| 1461040 | 18 |
| 1461050 | 18 |
| 1461060 | 18 |
| 1461066 | 41 |
| 1461100 | 18 |
| 1461140 | 18 |
| 1461150 | 18 |
| 1461160 | 18 |
| 1461300 | 18 |
| 1461350 | 18 |
| 1461360 | 18 |
| 1461965 | 40 |
| 1461SB | 25 |
| 1471360 | 22 |

| ITEM NO. | PAGE |
|----------|------|
| 1471460 | 22 |
| 1471461 | 22 |
| 1471462 | 33 |
| 1471601 | 19 |
| 1471602 | 33 |
| 1471ESM | 19 |
| 1471ESM | 33 |
| 1471MSM | 19 |
| 1471MSM | 33 |
| 1471PLM | 19 |
| 1471PLM | 33 |
| 1473190 | 12 |
| 1473292 | 30 |
| 1473597 | 30 |
| 1473692 | 30 |
| 1478060 | 15 |
| 1478080 | 15 |
| 1478050 | 15 |
| 1479040 | 14 |
| 1479070 | 14 |
| 1479090 | 14 |
| 1479091 | 31 |
| 1479092 | 31 |
| 1479291 | 31 |
| 1479292 | 31 |
| 1489090 | 14 |
| 1491008 | 24 |
| 1491010 | 24 |
| 1492008 | 24 |
| 1492010 | 24 |
| 1493008 | 24 |
| 1493010 | 24 |
| 1519100 | 10 |
| 1519100 | 28 |
| 1519140 | 10 |
| 1519140 | 28 |
| 1519150 | 10 |
| 1519150 | 28 |
| 1529100 | 8 |
| 1529140 | 8 |
| 1529160 | 8 |
| 1561000 | 17 |
| 1561030 | 17 |
| 1561040 | 17 |
| 1561050 | 17 |
| 1561060 | 17 |
| 1562050 | 17 |
| 1579000 | 11 |
| 1579002 | 29 |
| 1579040 | 11 |
| 1579042 | 29 |
| 1579050 | 11 |
| 1579052 | 29 |
| 1579100 | 11 |
| 1579140 | 11 |
| 1579150 | 11 |
| 1579200 | 11 |
| 1579202 | 29 |
| 1579240 | 11 |

| ITEM NO. | PAGE |
|----------|------|
| 1579242 | 29 |
| 1579250 | 11 |
| 1579252 | 29 |
| 1579300 | 11 |
| 1579340 | 11 |
| 1579350 | 11 |
| 1589200 | 8 |
| 1589240 | 8 |
| 1589260 | 8 |
| 1632490 | 22 |
| 1632497 | 22 |
| 1632500 | 20 |
| 1632602 | 20 |
| 1632ESM | 20 |
| 1632MSM | 20 |
| 1632PLM | 20 |
| 1662002 | 32 |
| 1662050 | 18 |
| 1662052 | 32 |
| 1662062 | 32 |
| 1679000 | 15 |
| 1679002 | 31 |
| 1679050 | 15 |
| 1679060 | 15 |
| 1679062 | 31 |
| 1679080 | 15 |
| 1679082 | 31 |
| 1694010 | 24 |
| 1804010 | 34 |
| 1976850 | 9 |
| 1977751 | 17 |
| 1979850 | 9 |
| 1987951 | 17 |
| 1989850 | 9 |
| 2201110 | 49 |
| 2206110 | 49 |
| 2407110 | 49 |
| 2421110 | 49 |
| 2441860 | 49 |
| 2451510 | 49 |
| 2491010 | 49 |
| 2505010 | 48 |
| 2505018 | 48 |
| 2505110 | 48 |
| 2505210 | 48 |
| 2506110 | 48 |
| 2518610 | 48 |
| 310D062 | 45 |
| 310D066 | 45 |
| 315D062 | 45 |
| 315D066 | 45 |
| 320D066 | 45 |
| 432D060 | 45 |
| 440D060 | 45 |
| 450D060 | 45 |
| 532D060 | 45 |
| 550D060 | 45 |
| 8632316 | 25 |
| ADP050 | 25 |

| ITEM NO. | PAGE |
|----------|------|
| ADP052 | 25 |
| BS13630 | 44 |
| DG-RJ45 | 50 |
| RJ45K13 | 50 |
| RJ45K23 | 50 |
| SEV-100 | 41 |
| SEV1148 | 40 |
| SEV12S2 | 39 |
| SEV13K2 | 39 |
| SEV15K2 | 39 |
| SEV15S | 39 |
| SEV23K2 | 38 |
| SEV23S | 38 |
| SEV25K2 | 38 |
| SEV25S | 38 |
| SEV313K | 39 |
| UL12500 | 44 |
| UL12505 | 44 |
| UL12506 | 44 |



ABL SURSUM
Bayerische Elektrozubehör GmbH & Co. KG

Albert-Büttner-Straße 11
D-91207 Lauf / Pegnitz

Tel. +49 (0) 9123 188-0
Fax +49 (0) 9123 188-188

info@abl.de
www.abl.de