

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2451300450

Status:


Active

Overview:

Nano-Fit Power Connectors

Description:

Nano-Fit-to-Nano-Fit Off-the-Shelf (OTS) Overmolded Cable Assembly, Dual Row, 5.0m Length, 4 Circuits, Black

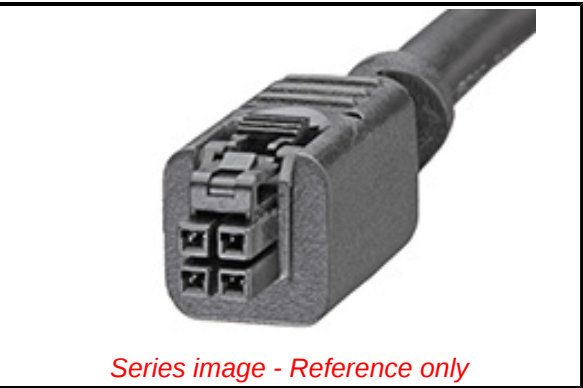

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	245130
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Nano-Fit-to-Nano-Fit
Overmolded	Yes
Overview	Nano-Fit Power Connectors
Product Name	Nano-Fit OTS
UPC	191128813853
Physical	
Cable Length	5.0m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Conductivity Copper
Material - Plating Mating	Matte Tin
Material - Plating Termination	Matte Tin
Material - Resin	Nylon
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	5.30mm
Wire Size AWG	20
Wire/Cable Type	UL 2464
Electrical	
Current - Maximum per Contact	7.0A
Voltage - Maximum	250V AC (RMS)
Material Info	
Reference - Drawing Numbers	
Sales Drawing	4000071377-000

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Not Reviewed

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

245130 Series

Mates With

Nano-Fit Headers 105309 , 105311 , 105313

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION