



fitted with

- work equipment
- connected load
- power consumption
- luminous flux
- luminous efficacy
- light distribution
- Beam Angle
- light colour
- color rendering index (CRI)
- system of protection
- class of protection
- technology
- usage
- luminaire body
- lamp cover
- tubular sections
- balance of articulation joints
- weight (net)
- mains lead
- fastening

special features


LED

- Energy efficiency category A+
- without
- 24 V; AC/DC
- approx. 6 W
- approx. 460 lm
- approx. 77 lm/W
- direct, wide-angled beam
- 30
- daylight white, approx. 5700 K
- > 72
- IP 65
- III
- switchable
- switch
- aluminium, anodised, black
- glass screen
- flexible metal tube, black
- friction
- approx. 1.3 kg
- approx. 3.0 m; with free stranded wires
- screw-down flange, magnetic base (accessory), table clamp (accessory), wall bracket (accessory)
- Flood with 40° angle of radiation



illuminance

Distance: 50 cm
Em: 3000 lx
Emax: 5958 lx
Emin: 721 lx

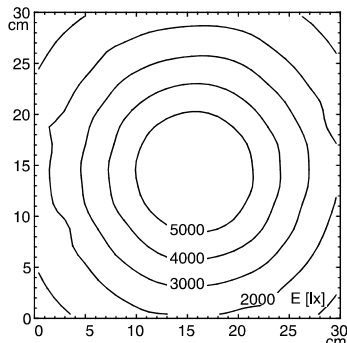

luminous intensity

