


# AC5031



## Lower part for AS-Interface module

EMS-BASE RC ST SET

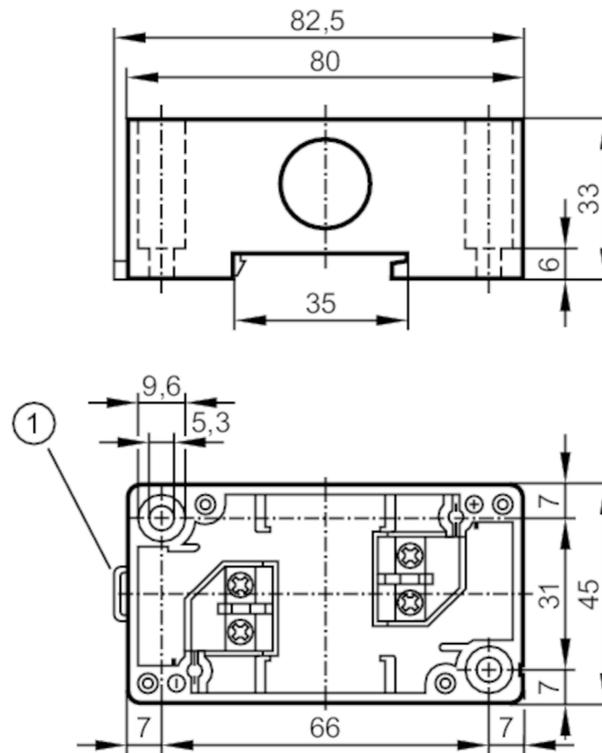

1 locking bolt

### Electrical data

Operating voltage [V] 26.5...31.6 DC

### Outputs

Electrical design AS-i

Contact rating < 4 A

### Operating conditions

Ambient temperature [°C] -25...85

Protection IP 65

### Mechanical data

Weight [g] 115.2

Housing rectangular

Type of mounting mounting on DIN rail and panel

Dimensions [mm] 82.5 x 45 x 33

Materials PBT

### Accessories

Items supplied flat cable seals: 2, NBR

cable glands: 3

Protective caps: 3

hexagon nuts: 4

Accessories (optional) cover:, for AS-i module, AC3000

screw terminal insert:, AC5007

### Remarks

Remarks up to 4 M20 cable ports for any T and cross branches

# AC5031



## Lower part for AS-Interface module

EMS-BASE RC ST SET

Pack quantity

1 pcs.

### Electrical connection

screw terminals: ...2.5 mm<sup>2</sup>