


# Data Sheet

## Alarm 4C SCR PVC

### Cross Section:

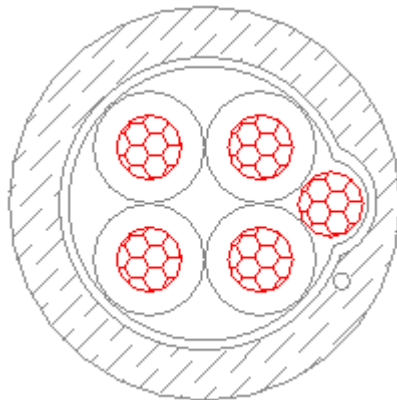

### Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V):300

### Construction:

Conductor: Tinned Copper Claded Aluminium

Conductor Dia. (mm): TCCA0.19±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 1.00±0.08 x 4C

### Al-Pet Shield

Coverage: ≥115%

Drain wire: Tinned Copper Claded Aluminium

Drain wire Dia. (mm): TCCA0.19±0.008 x 7

Nylon rip cord: 150D

Jacket: PVC

Outer Dia. (mm): 3.90±0.2

### Colour:

The color of the insulation: Red,Blue, Yellow,Black

The jacket color: According to customer

### Marking:

According to customer

### Performance:

#### Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :  
<177

Min.Insulation DC Resistance at 20°C (MΩ  
\*KM) : >200