
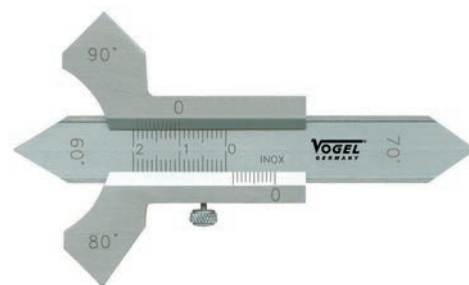
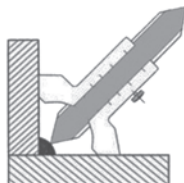


Welding Gauges

Precision Welding Gauge

- with vernier reading
- for measurements of flat welding seams and in corners etc.

 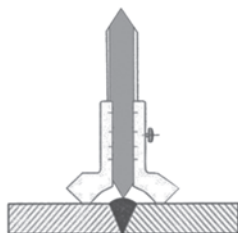


- stainless steel hardened and fine ground
- scale matt chromed
- with fixing screw



INOX




NORM

ART N°	 mm	 mm	angle °	 mm	CC
474403	0 – 20	0.1	60 / 70 / 80 / 90	98 x 59 x 5.2	on request

Electr. Digital Welding Gauge

- with data output RS 232 C

- stainless steel, hardened and ground
- LCD display with clear reading, zero-setting at any position
- On/Off button, reading switchable mm/inch
- incl. 1x 1.5 V battery (type LR44, art. no.: 90213), with operation manual

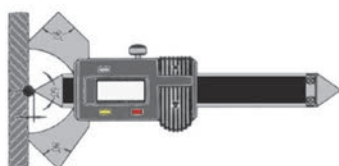

 

 

INOX



LR44 1.5V

RS232 C



NORM

ART N°	 mm / inch	 mm / inch	 max.	angle °	 mm	CC
474410	0 – 20 / 0 – 0.8	0.01 / 0.0005	0.03	60 / 70 / 80 / 90	100 x 62 x 14	on request


Precision Welding Gauge

- with reading window


- stainless steel, hardened and fine ground
- reading through a window by a reference line

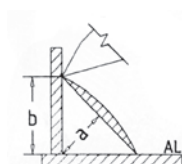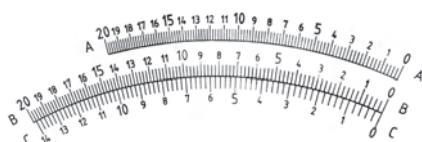

Read b from scale B.
When measuring b,
read a from scale C.

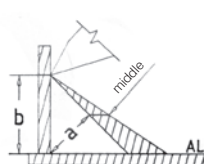

Permissible „a“
with unequal legs.
Rest on the
long arm (AL)

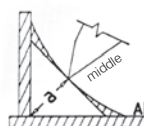



Read a from
scale A.



INOX



NORM

ART N°	 mm	 mm	CC
474404	0,1	108 x 81.5 x 3.2	on request