




LED FIL A70 E27 16W (150W) 2452lm 827 Clear

Article number: 143623

BAI LED Filament GLS A70 E27 16W 2700K Clear 2452lm (150W) 230V-240V 320° 70x125mm LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. Due to the warm 2700K light color, the lamps are also eye-friendly. The luminous flux is comparable to a 150W incandescent lamp.

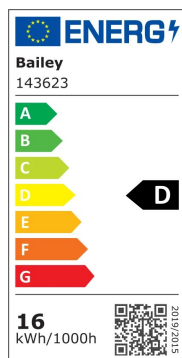

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL A70 E27 16W (150W) 2452lm 827 Clear
Brand	Bailey
Productseries	LED Filament GLS
Producttype	A70 E27 827 CL

ETIM specifications

Socket	E27
Luminous flux [lm]	2452 - 2452
Nominal voltage [V]	220 - 240
Lamp power [W]	16 - 16
Colour temperature [K]	2700 - 2700
Diameter [mm]	70
Length [mm]	125
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	2452
Power factor	0.9
Lamp efficacy [lm/W]	153
Nominal current [mA]	122 - 122
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	16
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	D
With twilight switch	No
Material of light bulb	Glass

Complementary articles



140440

Surge Protection Device (SPD)
10KV 110-277V IP65