



## SERIES 7 Quick Mini thickness Gauges/Pocket thickness Gauges

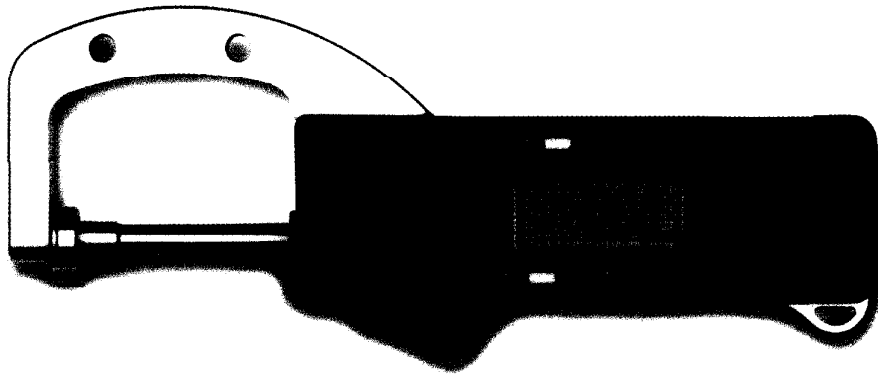

700-122

### Measurement applications

Ideal for measuring paper, leather, plastic, sheet metal and film.


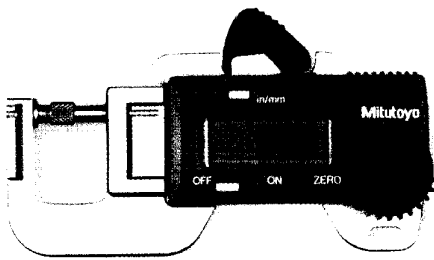


Series 7 Quick Mini model

RESOLUTION	RANGE	ACCURACY	NO.	PRICE
0.01mm/ 0.0005"	0-12mm/ 0-0.5"	±0.02mm/ ±0.001"	700-118	
0.01mm/ 0.0005"	0-25mm/ 0-1"	±0.02mm/ ±0.001"	700-122	

### Features

- ✓ Compact pocket sized Digimatic thickness gauge
- ✓ Imperial/metric conversion
- ✓ Measuring faces are hardened, ground and lapped

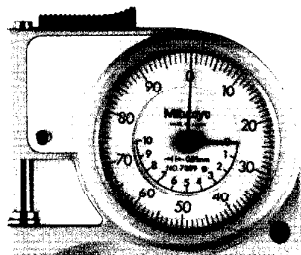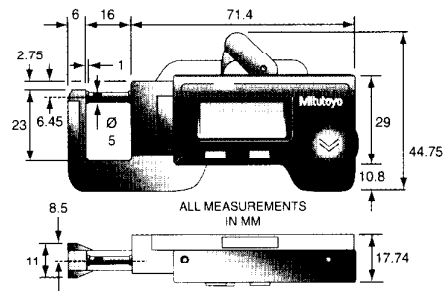

7309

### Measurement applications

Ideal for measuring paper, leather, plastic, sheet metal and film.

Series 7 Pocket thickness model

GRADUATION	RANGE	ACCURACY	NO.	PRICE
0.01mm	0-10mm	±20µm	7309	
0.001"	0-0.4"	±0.001"	7308	

### Features

- ✓ Compact pocket sized thickness gauge
- ✓ Preloaded spindle to provide a constant 0.2N (or less) measuring force
- ✓ Measuring faces are hardened, ground and lapped
- ✓ Easy zero adjustment

