

 

CONTI[®] SYNCHROBELT

Timing belts for the lower and medium power range

Properties:

- Temperature range from -20 °C to +100 °C depending on application
- Conditionally resistant to oil
- Ozone-resistant
- Suitable for tropical climates
- Resistant to aging
- Suitable for reverse flexing/reverse tensioning idlers
- Maintenance-free

Belt structure:

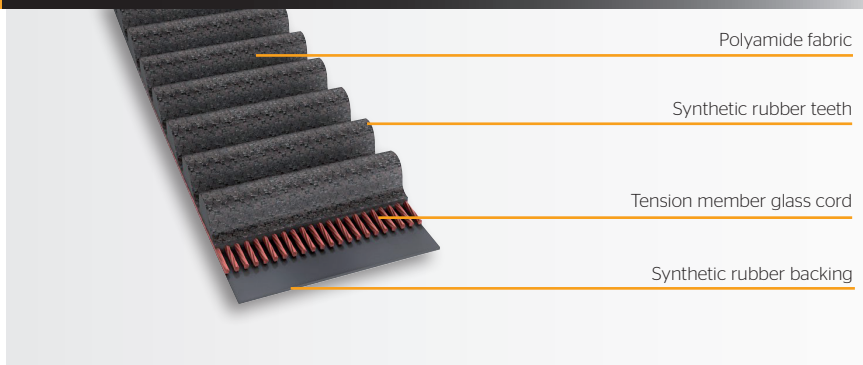

MXL - XXH

Profile	Length range L _p (1/10 inch)
MXL	43.2 - 404.0
XL	60.0 - 630.0
L	124.0 - 600.0
H	240.0 - 1700.0
XH	507.0 - 1750.0
XXH	700.0 - 1800.0

HTD

Profile	Length range L _p (mm)
HTD 3M	111 - 1569
HTD 5M	225 - 2525
HTD 8M	288 - 4400
HTD 14M	966 - 4578

STD

Profile	Length range L _p (mm)
STD S8M	440 - 2848

The content of this publication is not legally binding and is provided as information only. The trademarks displayed in this publication are the property of Continental AG and/or its affiliates. Copyright © 2015 ContiTech AG. All rights reserved. For complete information go to: www.contitech.de/disc/en

Power Transmission Group

ContiTech Antriebssysteme GmbH
D-30169 Hannover · Phone +49 511 938 - 71
industrie.as@ptg.contitech.de