




CWT 9002

E0870985

SOLDERSLEEVE WIRE SPLICE RED, OD MAX=2.8mm, 0.6-2.0mm²

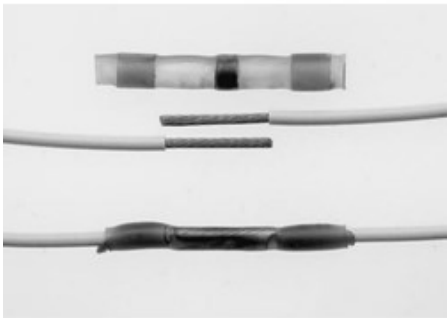

Product Properties:

Colour	Red
Operating temperature	-55-125 °C
Voltage max	600V
Halogen free	Yes
Connector type	Lödskarvhylsa med lim

Dimensions:

MOQ	100 .
Unit	pcs
Nominal cross section	0.6-2 mm ²

Approvals:

With approval according to UL	Yes
-------------------------------	-----

Compliance:

Conflict Minerals	Yes, see report under tab "Documents"
Iron and Steel Sanction	Compliance
Link to manufacturer COC	https://www.te.com/commerce/alt/SinglePartSearch.do?PN=470037-000
REACH	Yes. CAS 7439-92-1, 32 %, CAS 7440-43-9, 18 %
RoHS	No
SCIP	1ecdf4b6-d2e1-43c9-be43-8f03e55b0d92
ECCN (EU)	No CLASS
ECCN (US)	EAR99

Other information:

ETIM-Class	EC000466 - Heat-shrink crimp connection
ETIM-Release	9.0
Trademark	TE Connectivity
Product Group	Soldersleeve wire splices
Search Description	470037-000, CWT-9002
Alternative SKU	CWT9002
E-no	E0870985

Logistic information:

Barcode	733117611726
Country of origin	MX
E-no	E0870985
Item status	Stock item, normally in stock with reservation for in between sales.
MOQ	100 .
Stock code	CWT 9002
Taric code	85369010
Unit	pcs

*We reserve the right to make technical changes and disclaim any typographical errors.