

---

## PARATHOM RF CLASSIC A 60 7 W/827 E27

PARATHOM Retrofit advanced CLASSIC A | Dimmable LED lamps, classic bulb shape



---

### Areas of application

- Perfect for decorative installations
- Domestic applications
- General illumination
- Outdoor applications only in suitable luminaires

---

### Product benefits

- Design, dimensions, luminous flux comparable to an incandescent or halogen lamp
- Very low energy consumption
- Robust against vibrations
- Extremely long life
- No UV and near-IR radiation in the light beam
- Instant 100 % light, no warm-up time
- Can be easily fitted instead of ordinary light bulbs
- Lower thermal output (compared with the standard reference product)

---

### Product features

- Professional LED lamps for line voltage
- Dimmable
- Base: E27
- Mercury-free lamps
- Lifetime: up to 15,000 h



Technical data

Electrical data

Rated wattage	7.00 W
Nominal wattage	7.00 W
Nominal voltage	220...240 V
Operating frequency	50...60 Hz
Power factor $\lambda$	> 0.50
Claimed equiv. conventional lamp power	60 W


Photometrical data

Nominal luminous flux	806 lm
Rated luminous flux	806 lm
Color temperature	2700 K
Color rendering index Ra	$\geq 80$
Light color (designation)	Warm White
Standard deviation of color matching	$\leq 6$ sdc <sub>m</sub>

Light technical data

Warm-up time (60 %)	< 1.00 s
Starting time	< 0.5 s

Dimensions & weight

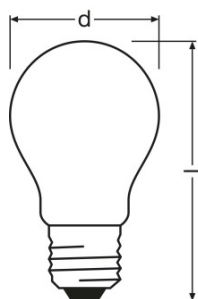

Overall length	105.0 mm
Diameter	60.0 mm
Outer bulb	A60
Length	105.0 mm

Lifespan

## Product datasheet

Nominal lamp life time	15000 h
Rated lamp life time	15000 h
Number of switching cycles	100000
Lumen main.fact.at end of nom.life time	0.70
Lumen maintenance at end of service life	0.70

### Additional product data

Base (standard designation)	E27
Mercury content	0.0 mg
Mercury-free	Yes
Design / version	Frosted
Appropriate disposal acc. to WEEE	Yes

### Capabilities

Dimmable	Yes
----------	-----

### Certificates & standards

Energy efficiency class	A+
Energy consumption	7 kWh/1000h

### Country specific categorizations

ILCOS	DRAA/F-6,5/827-220-240-E27-60
Order reference	PRFCLA60DI 7W/8

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899959088	PARATHOM RF CLASSIC A 60 7 W/827 E27	Shipping carton box 10	315 mm x 131 mm x 126 mm	5.20 dm <sup>3</sup>	553.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.