


Datasheet

Single Screw Polyamide Terminal Blocks

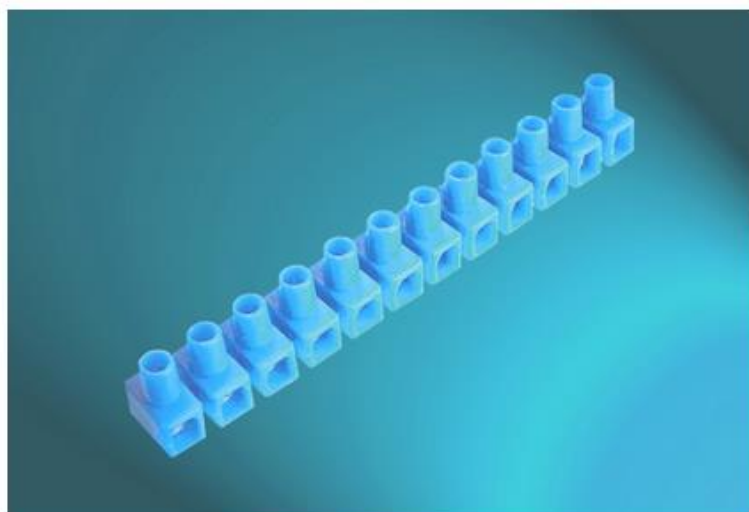

SPECIFICATIONS	
INSERTS:	BRASS
HOUSING:	POLYAMIDE (PA 66)
TEMPERATURE:	105 °C
SCREWS:	GALVANISED STEEL
APPROVALS:	CE (BS EN 60998)
COLOURS:	BLACK, BLUE, BROWN, GREEN
FEATURES:	Semi-rigid and easy cut Flame retardant All screws are captive and raised for easy wiring

RS Stock No.	COLOUR	CROSS SECTION	CURRENT RANGE	RATED VOLTAGE	DIMENSIONS (mm)					
					W	L	φ	D	H	h
867-0981	Black	2.5 mm ²	24 A	400 V	14	122	3.3	10	18	10
867-0985	Blue									
867-0994	Brown									
867-0997	Green									

Cross-section rated for rigid wire and cables (if for flexible wire, it should be reduced one-step, i.e., 6mm² is 4mm²)

φ1 = wire entry hole diameter

φ2 = fixing hole diameter