


**Datasheet**

**Stock No: 402-664**

## **RS Pro 2.54mm Pitch 16 Way**

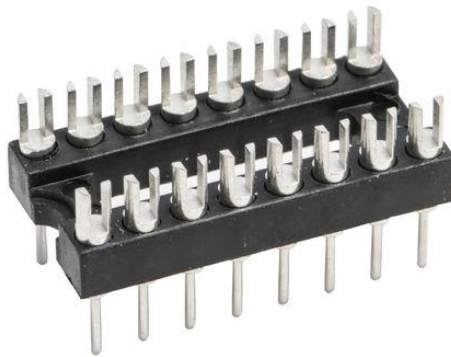

### **Product Details**

#### **Slotted Header**

A range of slotted Dual In Line (DIL) headers designed to facilitate building of sub-assemblies or modules for use as a carrier system. May also be used with appropriate DIL sockets to form a plug and socket pair for multi-way connections or directly soldered into PCBs.

Pin spacing : 2.54mm

Operating temperature -55°C → +150°C

Flammability UL 94 V-0

#### **IC Sockets-Components Headers**

## Specifications:

Number of Contacts	16
Contact Material	Brass
Contact Plating	Tin over Nickel
Pitch	2.54mm
Termination Method	Solder
Mounting Type	Through Hole
Housing Material	PBT
Current Rating	1A
Depth	10.14mm
Length	20.24mm
Maximum Operating Temperature	+150°C
Minimum Operating Temperature	-65°C