


vacuum suction cup ESV-30-CS

Part number: 191074

FESTO

Wearing part, easily replaceable

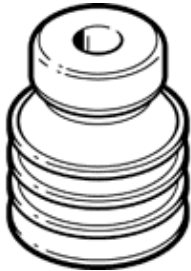

Data sheet

Feature	Value
Suction cup height compensator	10.5 mm
Min. workpiece radius	80 mm
suction cup diameter	30 mm
suction cup volume	9.47 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows, 3.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Food-safe	See Supplementary material information
Ambient temperature	-30 ... 180 °C
Retention force at nominal operating pressure	20.8 N
Product weight	5.8 g
Colour	transparent
Shore hardness	50 +/- 5
Materials note	Free of copper and PTFE Contains PWIS substances Conforms to RoHS
Material suction cup	VMQ (silicon)