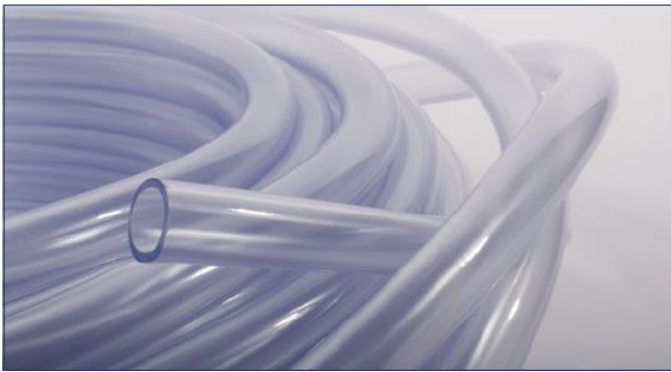


Datasheet

Stock No: 9145509**RS Pro Clear Unreinforced PVC Hose**

Nominal Size	10 x 15mm
Internal Diameter	12.0 ± 0.50mm
External Diameter	15.0 ± 1.00mm
Length Tolerance	BS EN ISO 1307 (± 1%)
Maximum Working Pressure	N/A
Minimum Burst Pressure	N/A
Bend Radius	135mm
Working Temperature	-15°C to +60°C
Material	Flexible PVC
Material Softness	BSS45 FDA Approved
Flammability	Self-Extinguishing
Weight Per Meter	0.092Kg
Coil Weight	2.75Kg