


Datasheet

Recessed Countersunk Machine Screws Stainless Steel A2-304 DIN 965

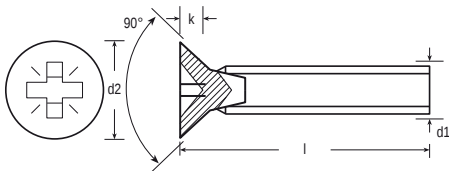

d1	M1.6	M2	M2.5	M3	M3.5	M4	M5	M6	M8
d2	3.00	3.80	4.70	5.60	6.50	7.50	9.20	11.00	14.50
k	<i>max.</i> 0.96	1.20	1.50	1.65	1.93	2.20	2.50	3.00	4.00
Recess	<i>no.</i> 0	1	1	1	2	2	2	3	4

Please view our full range listing below

RS Stock No	Size (mm)	RS Stock No	Size (mm)	RS Stock No	Size (mm)	RS Stock No	Size (mm)	RS Stock No	Size (mm)
1795664	M1.6 × 3	1795673	M2.5 × 5	9141771	M3 × 16	9141797	M5 × 8	529040	M6 × 20
1795665	M1.6 × 4	1795674	M2.5 × 6	528968	M3 × 20	9141807	M5 × 10	529056	M6 × 25
1795666	M1.6 × 5	1795675	M2.5 × 8	9141775	M3 × 25	529006	M5 × 12	9141829	M6 × 30
1795667	M1.6 × 6	1795676	M2.5 × 10			7976351	M5 × 16	9141822	M6 × 35
		1795677	M2.5 × 12	9141784	M4 × 5	529012	M5 × 20	9141826	M6 × 40
9141759	M2 × 4	1795678	M2.5 × 16	7976349	M4 × 6	529028	M5 × 25	9141835	M6 × 45
1795668	M2 × 5	1795679	M2.5 × 20	9141787	M4 × 8	7976355	M5 × 30	9141838	M6 × 50
9141753	M2 × 6	1795680	M2.5 × 25	7976358	M4 × 10	9141800	M5 × 35		
9141762	M2 × 8			528974	M4 × 12	9141804	M5 × 40	9141832	M8 × 25
1795670	M2 × 10	9141765	M3 × 5	528980	M4 × 16	9141813	M5 × 50	9141841	M8 × 30
1795671	M2 × 12	528946	M3 × 6	528996	M4 × 20			9141844	M8 × 40
1795669	M2 × 16	9141769	M3 × 8	9141781	M4 × 25	9141816	M6 × 10		
		9141778	M3 × 10	9141790	M4 × 30	529034	M6 × 12		
1795672	M2.5 × 4	528952	M3 × 12	9141793	M4 × 40	9141810	M6 × 16		