

Incremental hollow shaft encoder BHK

assignment cable

for connection reference **-5**

05A (5 VDC complementary)

cable color	signals
brown	+Vs
green	CHA
red	CHA compl.
yellow	CHB
blue	CHB compl.
pink	CHN
grey	CHN compl.
white	0V
screen	connected to flange
cable data	8x 0,14 mm ² , max. ext. ø 5,7 mm

24K (10 - 30 VDC push-pull, short-circuit protection)

cable color	signals
brown	+Vs
green	CHA
yellow	CHB
pink	CHN
white	GND
screen	connected to flange
cable data	5x 0,14 mm ² , max. ext. ø 5,4 mm

assignment connector


for connection reference **-9**



05A (5 VDC complementary)

pin number	signals
1	0V
2	+Vs
3	CHA
4	CHB
5	CHN compl.
6	CHN
7	CHB compl.
8	CHA compl.

for connection reference **-9**

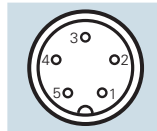

24K (10 - 30 VDC push-pull, short-circuit prot.)

pin number	signals
1	0V
2	+Vs
3	CHA
4	CHB
5	CHN

Note

When using the pre-assembled cable socket, please observe the operating instructions.